


# Axial kit EAMM-A-M43-70AA

Part number: 8063535

FESTO

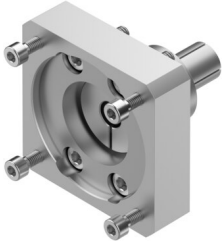

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	27.9 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	14.5 kgmm <sup>2</sup>
Transmittable torque	12.5 Nm
Product weight	460 g
Interface code, actuator	M43
Interface code, motor in	70AA 70AB
Note on materials	RoHS-compliant