


Axial kit EAMM-A-N48-75GA

Part number: 8063598

FESTO

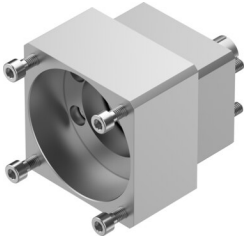

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	74.5 mm
Mounting position	optional
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	39 kgmm ²
Transmittable torque	17 Nm
Product weight	848 g
Interface code, actuator	N48
Interface code, motor in	75GA
Note on materials	RoHS-compliant