


Axial kit EAMM-A-N48-72GA

Part number: 8063601

FESTO

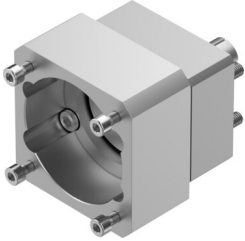

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	66.5 mm
Mounting position	optional
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	39 kgmm ²
Transmittable torque	17 Nm
Product weight	739 g
Interface code, actuator	N48
Interface code, motor in	72GA
Note on materials	RoHS-compliant