


# Axial kit EAMM-A-N48-90GB

Part number: 8063602

FESTO

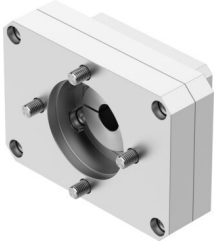

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	54.5 mm
Mounting position	optional
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	39 kgmm <sup>2</sup>
Transmittable torque	17 Nm
Product weight	1378 g
Interface code, actuator	N48
Interface code, motor in	90GB
Note on materials	RoHS-compliant