


# Sub-base VMPA14-AP-4-1-EMM-8

Part number: 8066780

FESTO

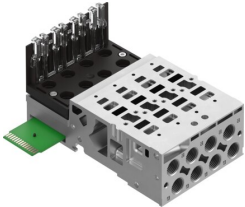

 [General operating condition](#)

## Data sheet

| Feature                        | Value                   |
|--------------------------------|-------------------------|
| Width                          | 65.5 mm                 |
| Length                         | 107.3 mm                |
| Grid dimension                 | 14.8 mm                 |
| Max. number of valve positions | 4                       |
| Operating pressure             | -0.09 MPa ... 1 MPa     |
| Operating pressure             | -0.9 bar ... 10 bar     |
| Pilot pressure                 | 0.3 MPa ... 0.8 MPa     |
| Pilot pressure                 | 3 bar ... 8 bar         |
| Corrosion resistance class CRC | 0 - No corrosion stress |
| LABS (PWIS) conformity         | VDMA24364-B1/B2-L       |
| Ambient temperature            | -5 °C ... 50 °C         |
| Product weight                 | 252 g                   |
| Pneumatic connection, port 2   | G1/8                    |
| Pneumatic connection, port 4   | G1/8                    |
| Note on materials              | RoHS-compliant          |
| Material sub-base              | Die-cast aluminium      |