


# Manifold rail VABM-P7-18M-G18-M5-6

Part number: 8076388

FESTO

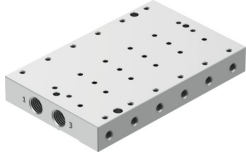

 [General operating condition](#)

## Data sheet

| Feature                                   | Value                         |
|---|-------------------------------|
| Grid dimension                            | 18 mm                         |
| Design                                    | Connection direction at side  |
| Max. number of valve positions            | 6                             |
| Corrosion resistance class CRC            | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity                    | VDMA24364-B2-L                |
| Max. tightening torque for valve mounting | 0.6 Nm                        |
| Product weight                            | 270 g                         |
| Pneumatic connection, port 1              | G1/8                          |
| Pneumatic connection, port 2              | M5                            |
| Note on materials                         | RoHS-compliant                |
| Material manifold rail                    | Wrought aluminium alloy       |