


# Manifold rail VABM-P7-18MB-G18-M5-6

Part number: 8076389

FESTO

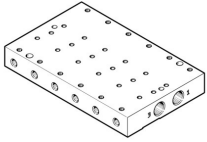

 [General operating condition](#)

## Data sheet

Feature	Value
Grid dimension	18 mm
Design	Connection direction downwards
Max. number of valve positions	6
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Max. tightening torque for valve mounting	0.6 Nm
Product weight	270 g
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	M5
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy