


Axial kit EAMM-A-V32-38AA

Part number: 8093023

FESTO

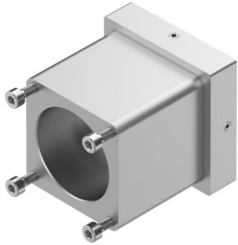

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------|------------------------|
| Nominal length | 46 mm |
| Mounting position | optional |
| Max. rotational speed | 10000 rpm |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95% |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 0.19 kgmm ² |
| Transmittable torque | 1.5 Nm |
| Product weight | 112 g |
| Interface code, actuator | V32 |
| Interface code, motor in | 38AA |
| Note on materials | RoHS-compliant |