


# Axial kit EAMM-A-V32-40RA

Part number: 8094180

FESTO

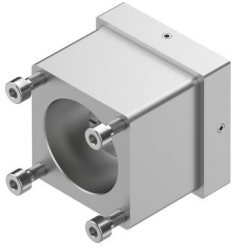

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	39 mm
Mounting position	optional
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	0.19 kgmm <sup>2</sup>
Transmittable torque	1.5 Nm
Product weight	114 g
Interface code, actuator	V32
Interface code, motor in	40RA
Note on materials	RoHS-compliant