


# Filter flow control CAMF-C6-FD-C6-11A

Part number: 8096867

FESTO

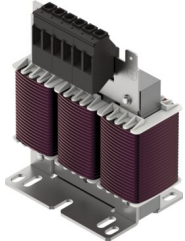

 General operating condition

## Data sheet

Feature	Value
Short circuit current rating	No
Current rating at 40° C	6 A
Operational voltage range AC	0 V ... 600 V
Nominal inductance	3.7 mH
Nominal inductance tolerance	10 %
Mains frequency	50 Hz ... 60 Hz
Insulation voltage	4000 V
Dimensions (W x L x H)	60 mm x 80 mm x 116 mm
Approval	ENEC c UL - Recognized (OL)
CE mark (see declaration of conformity)	In accordance with EU RoHS Directive
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-10 °C ... 40 °C
Degree of protection	IP00
Ambient temperature	-10 °C ... 40 °C
Product weight	940 g
Type of mounting	Mounting plate, attached with screws
Note on materials	RoHS compliant
Mounting position	Horizontal
Electrical connection 1, function	Power supply
Electrical connection 1, connection type	Terminal strip
Electrical connection 1, connector system	Screw terminal
Electrical connection 1, number of connections/cores	6
Electrical connection 1, used connections/cores	6
Electrical connection 1, conductor cross section	4 mm <sup>2</sup>