


# Axial kit EAMM-A-D32-60AA

Part number: 8105887

FESTO

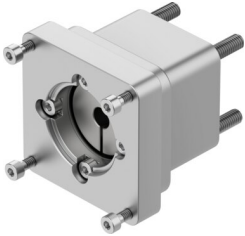

 [General operating condition](#)

## Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transmittable torque	6.5 Nm
Product weight	341 g
Interface code, actuator	D32
Interface code, motor in	60AA
Note on materials	RoHS-compliant