


Axial kit EAMM-A-D60-84AA

Part number: 8105945

FESTO

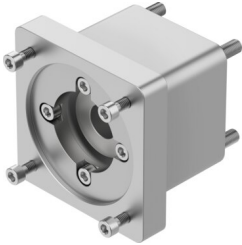

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	75 mm
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transmittable torque	21 Nm
Product weight	1190 g
Interface code, actuator	D60
Interface code, motor in	84AA
Note on materials	RoHS-compliant