


# Axial kit EAMM-A-P5-28B-38AA

Part number: 8107710

FESTO

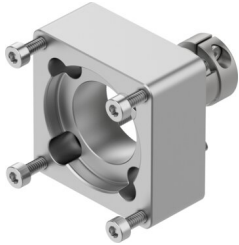

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	17.5 mm
Mounting position	optional
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	0.28 kgmm <sup>2</sup>
Transmittable torque	1.1 Nm
Product weight	59 g
Interface code, actuator	P5-28B
Interface code, motor in	38AA
Interface code, clutch housing	28B
Note on materials	RoHS-compliant