


Axial kit EAMM-A-D80-84AA

Part number: 8110055

FESTO

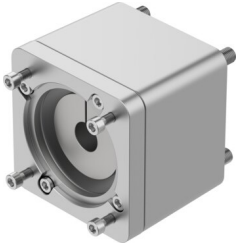

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	85 mm
Mounting position	optional
Max. rotational speed	5500 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	128 kgmm ²
Transmittable torque	60 Nm
Product weight	1780 g
Interface code, actuator	D80
Interface code, motor in	84AA
Note on materials	RoHS-compliant