


Vertical pressure supply plate VMPA14-VSP-QS1/4

FESTO

Part number: 8110626

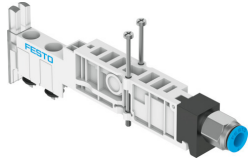

 General operating condition

Data sheet

Feature	Value
Grid dimension	14 mm
Symbol	00991883
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C ... 50 °C
Product weight	35 g
Pneumatic connection, port 1	QS-1/4
Note on materials	RoHS-compliant
Material supply plate	PA-reinforced