


Sub-base VABS-K2-10B-16-M6-P

Part number: 8122825

FESTO

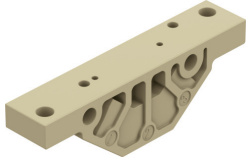

 [General operating condition](#)

Data sheet

| Feature | Value |
|---|---|
| Size | 10 |
| Nominal size | 1.6 mm |
| Fluid connection | M6 female thread |
| Mounting position | optional |
| Design | Connection direction downwards |
| Max. number of valve positions | 1 |
| Flow direction | Non-reversible |
| Operating medium | Liquid media Gaseous media |
| Note on operating and pilot medium | Observe resistance of materials that come into contact with the media |
| Corrosion resistance class CRC | 0 - No corrosion stress |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Storage temperature | -20 °C ... 70 °C |
| Media temperature | 0 °C ... 50 °C |
| Ambient temperature | 0 °C ... 50 °C |
| Max. tightening torque for valve mounting | 0.2 Nm |
| Product weight | 7 g |
| Mounting method for sub-base | With through-hole |
| Mounting method for valve | Via female thread |
| Note on materials | RoHS-compliant |
| Material sub-base | PEEK |