


Sub-base VABS-K2-10B-16-U14-P

Part number: 8122826

FESTO

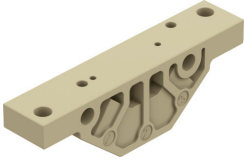

 General operating condition

Data sheet

Feature	Value
Size	10
Nominal size	1.6 mm
Fluid connection	Female thread 1/4-28 UNF-2B
Mounting position	optional
Design	Connection direction downwards
Max. number of valve positions	1
Flow direction	Non-reversible
Operating medium	Liquid media Gaseous media
Note on operating and pilot medium	Observe resistance of materials that come into contact with the media
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C ... 70 °C
Media temperature	0 °C ... 50 °C
Ambient temperature	0 °C ... 50 °C
Max. tightening torque for valve mounting	0.2 Nm
Product weight	7 g
Mounting method for sub-base	With through-hole
Mounting method for valve	Via female thread
Note on materials	RoHS-compliant
Material sub-base	PEEK