


Sub-base VABS-K2-10S-16-M6-P

Part number: 8122827

FESTO

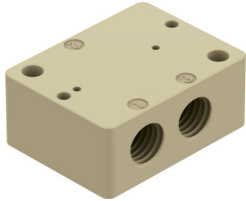

 General operating condition

Data sheet

Feature	Value
Size	10
Nominal size	1.6 mm
Fluid connection	M6 female thread
Mounting position	optional
Design	Connection direction at side
Max. number of valve positions	1
Flow direction	Non-reversible
Operating medium	Liquid media Gaseous media
Note on operating and pilot medium	Observe resistance of materials that come into contact with the media
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C ... 70 °C
Media temperature	0 °C ... 50 °C
Ambient temperature	0 °C ... 50 °C
Max. tightening torque for valve mounting	0.2 Nm
Max. tightening torque	0.6 Nm
Product weight	7 g
Mounting method for sub-base	With through-hole
Mounting method for valve	Via female thread
Note on materials	RoHS-compliant
Material sub-base	PEEK