


Axial kit EAMM-A-D80-150A-S1

Part number: 8157274

FESTO

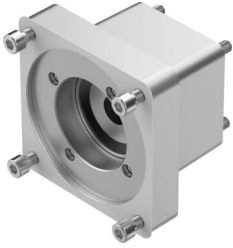

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	103.5 mm
Mounting position	optional
Max. rotational speed	5500 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	128 kgmm ²
Transmittable torque	60 Nm
Product weight	3068 g
Interface code, actuator	D80
Interface code, motor in	140A 150A
Note on materials	RoHS-compliant