


Axial kit EAMM-A-D100-150A

Part number: 8157275

FESTO

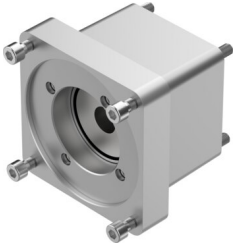

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	102 mm
Mounting position	optional
Max. rotational speed	4500 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	280 kgmm ²
Transmittable torque	143 Nm
Product weight	3433 g
Interface code, actuator	D100
Interface code, motor in	140A 150A
Note on materials	RoHS-compliant