


Axial kit EAMM-A-K95-150A

Part number: 8157278

FESTO

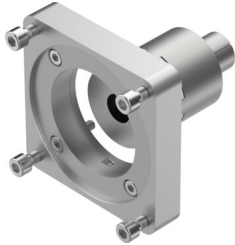

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------|------------------|
| Mounting position | optional |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95% |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C ... 60 °C |
| Transmittable torque | 143 Nm |
| Product weight | 1986 g |
| Interface code, actuator | K95 |
| Interface code, motor in | 140A 150A |
| Note on materials | RoHS-compliant |