


# Parallel kit EAMM-U-145-D100-150A-188-S1

Part number: 8157284

FESTO

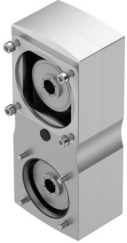

 [General operating condition](#)

## Data sheet

Feature	Value
Size	145
Mounting position	optional
Gear unit ratio	1:1
Max. rotational speed	4000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	2255 kgmm <sup>2</sup>
Frictional torque independent of load	2 Nm
Transmittable torque	50 Nm
Product weight	11500 g
Interface code, actuator	D100B
Interface code, motor in	140A 150A
Note on materials	RoHS-compliant