


Axial kit EAMM-A-T46-57A

Part number: 8169409

FESTO

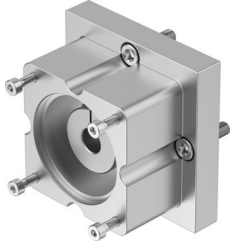

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	42 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	3.2 kgmm ²
Transmittable torque	6 Nm
Product weight	395 g
Interface code, actuator	T46
Interface code, motor in	57A
Note on materials	RoHS-compliant