


Adapter plate VABA-C13-100-1-F90-G12-G14

FESTO

Part number: 8189576

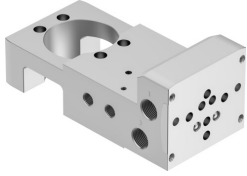

 General operating condition

Data sheet

Feature	Value
Size	180 240 300 360 480 700 720 900
Mounting position	Any
Design	Adapter for rotary actuator
Valve connection conforms to standard	VDI/VDE 3845-1
Operating pressure	0 MPa ... 0.9 MPa
Operating pressure	0 bar ... 9 bar
Explosion protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air to ISO 8573-1:2010 [7:7:-] Inert gas
Note on operating and pilot medium	Lubricated operation not possible
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Media temperature	-40 °C ... 80 °C
Ambient temperature	-40 °C ... 80 °C
Product weight	2530 g
Type of mounting	With accessories
Pneumatic connection	Sub-base design, airing
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G1/4
Pneumatic connection, port 3	G1/2
Pneumatic connection, port 4	G1/4
Note on materials	RoHS compliant
Material cover	Smooth-anodised wrought aluminium alloy (20 µm)
Material seals	EPDM NBR
Material housing	Smooth-anodised wrought aluminium alloy (20 µm)
Material screws	High-alloy stainless steel