


Adding counter PZA-E-C

Part number: 8606

FESTO

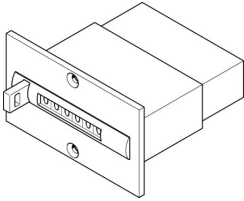

 [General operating condition](#)

Data sheet

Feature	Value
Design	Mechanical sequence counter with pneumatic drive
Type of reset	Pushbutton or pneumatic signal
Display	6 characters
Drop-off pressure drive	< 0.15 bar
Drop-off pressure reset	< 0.15 bar
Response pressure drive	> 0.8 bar
Response pressure reset	2 bar
Operating pressure	2 bar ... 8 bar
Min. reset pressure	2 bar
Min. pulse length drive	8 ms
Min. pulse length reset	150 ms
Min. pause period drive	10 ms
Min. pause period reset	50 ms
Explosion protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	0 °C ... 60 °C
Product weight	70 g
Type of mounting	Front panel mounting
Pneumatic connection	M5
Material housing	Process automation