
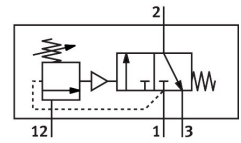


# Pressure sequence valve VD-3-PK-3

Part number: 9270

FESTO

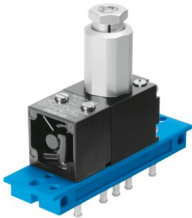

[PDF](#) General operating condition

## Data sheet

Feature	Value
Standard nominal flow rate (standardised to DIN 1343)	100 l/min
pneumatic working port	PK-3
Operating pressure	0.18 MPa ... 0.8 MPa
Operating pressure	1.8 bar ... 8 bar
Nominal size	2.5 mm
Symbol	00991739
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-10 °C ... 60 °C
Product weight	220 g
Type of mounting	With through-hole
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Pneumatic connection, port 3	PK-3
Note on materials	RoHS-compliant