


Bulkhead quick connector SCK-PK-3-KU

Part number: 9387

FESTO

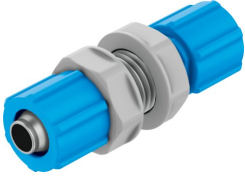

 [General operating condition](#)

Data sheet

| Feature | Value |
|---|--|
| Nominal size | 2.4 mm |
| Mounting position | optional |
| Design | Bulkhead |
| Size of pack | 10 |
| Operating pressure complete temperature range | -0.095 MPa ... 1 MPa |
| Operating pressure complete temperature range | -0.95 bar ... 10 bar |
| Operating pressure complete temperature range | -13.775 psi ... 145 psi |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C ... 60 °C |
| Pneumatic connection, port 1 | For tubing outer diameter of 4 mm For barbed fitting I.D. 3 mm with union nut |
| Pneumatic connection, port 2 | For tubing outside diameter of 4 mm For barbed fitting I.D. 3 mm with nut |
| Material union nut | POM |
| Note on materials | RoHS-compliant |
| Material nut | POM |
| Material connector | POM |