


## Inscription label holder

**FESTO**

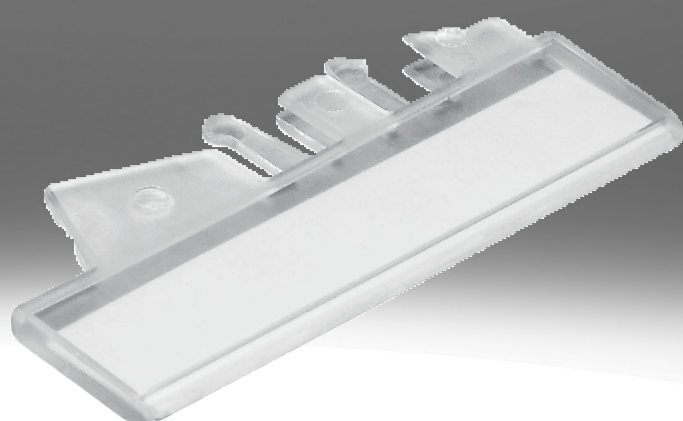

## Type code

| 001         | Series              |  |
|-------------|---------------------|--|
| CPV18-BZ_ST | Label holder CPV18  |  |
| VMPAL-ST    | Label holder VMPAL  |  |
| ASCF        | Label holder ASCF   |  |
| CPX-ST      | Label holder CPX    |  |
| CPVSC1-ST   | Label holder CPVSC1 |  |
| CPV10-BZ_ST | Label holder CPV10  |  |
| VMPA14-ST   | Label holder VMPA14 |  |
| VMPA1-ST    | Label holder VMPA1  |  |
| CPV14-BZ_ST | Label holder CPV14  |  |

| 002 | Designation element             |  |
|-----|---------------------------------|--|
| H   | Label holder                    |  |
| M   | Label holder for manifold block |  |
| P1  | Profile 1                       |  |
| P3  | Profile 3                       |  |
| R   | Retainer                        |  |
| RP1 | Profile 1 incl. holder          |  |
| RP3 | Profile 3 incl. holder          |  |
| T   | Label holder, transparent       |  |

| 003 | Allocation  |  |
|-----|-------------|--|
| E2  | Version E2  |  |
| L1  | Version L1  |  |
| L2  | Version L2  |  |
| P11 | Version P11 |  |
| S1  | Version S1  |  |
| S2  | Version S2  |  |
| S6  | Version S6  |  |


| 004 | Size          |  |
|-----|---------------|--|
|     | Standard      |  |
| 2   | Size 2        |  |
| 10  | Size 10       |  |
| 14  | Size 14       |  |
| 18  | Size 18/18 mm |  |
| 1   | Size 1        |  |

| 005 | Valve positions    |  |
|-----|--------------------|--|
|     | None               |  |
| 2V  | 2 valve positions  |  |
| 3V  | 3 valve positions  |  |
| 4V  | 4 valve positions  |  |
| 5V  | 5 valve positions  |  |
| 6V  | 6 valve positions  |  |
| 7V  | 7 valve positions  |  |
| 8V  | 8 valve positions  |  |
| 9V  | 9 valve positions  |  |
| 10V | 10 valve positions |  |
| 11V | 11 valve positions |  |
| 12V | 12 valve positions |  |
| 13V | 13 valve positions |  |
| 14V | 14 valve positions |  |
| 15V | 15 valve positions |  |
| 16V | 16 valve positions |  |
| 17V | 17 valve positions |  |
| 18V | 18 valve positions |  |
| 19V | 19 valve positions |  |
| 20V | 20 valve positions |  |
| 21V | 21 valve positions |  |
| 22V | 22 valve positions |  |
| 23V | 23 valve positions |  |
| 24V | 24 valve positions |  |

| 006 | Version                    |  |
|-----|----------------------------|--|
|     | Standard                   |  |
| Z   | With additional checkboxes |  |

## Datasheet

### Materials – Label holder with inscription label IBS-6x10 for valve terminals CPV

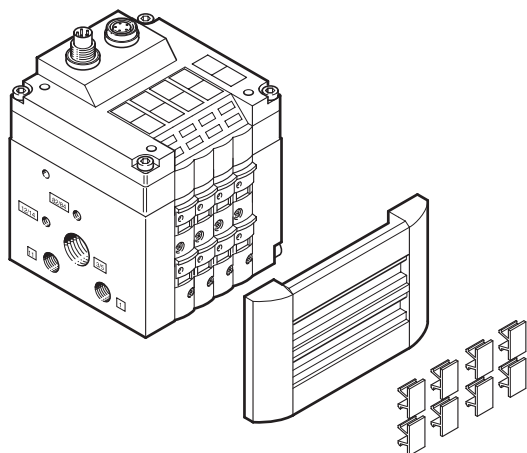


|                        |                   |
|------------------------|-------------------|
| Material label holder  | –                 |
| Material screen        | –                 |
| Note on materials      | RoHS compliant    |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |

### Operating and environmental conditions – Label holder with inscription label IBS-6x10 for valve terminals CPV

|                                                 |   |
|-------------------------------------------------|---|
| Corrosion resistance class<br>CRC <sup>1)</sup> | – |
|-------------------------------------------------|---|

<sup>1)</sup> More information [www.festo.com/x/topic/kbk](http://www.festo.com/x/topic/kbk)

### Materials – Label holder with inspection window for valve terminals CPV

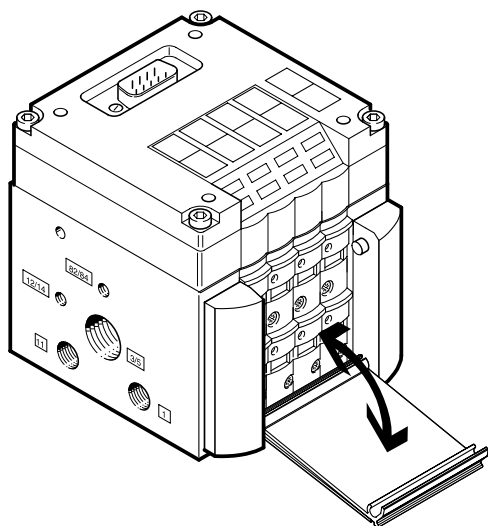

|                        |                   |
|------------------------|-------------------|
| Material label holder  | –                 |
| Material screen        | PVC               |
| Note on materials      | RoHS compliant    |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |


### Operating and environmental conditions – Label holder with inspection window for valve terminals CPV

|                                                 |                               |
|-------------------------------------------------|-------------------------------|
| Corrosion resistance class<br>CRC <sup>1)</sup> | 2 - Moderate corrosion stress |
|-------------------------------------------------|-------------------------------|

<sup>1)</sup> More information [www.festo.com/x/topic/kbk](http://www.festo.com/x/topic/kbk)


Datasheet

Materials – Label holder for valve terminals CPV-SC

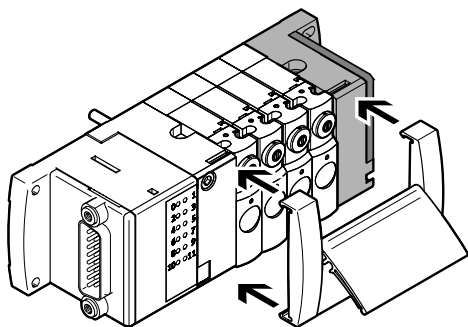

|                        |                |
|------------------------|----------------|
| Material label holder  | PVC            |
| Note on materials      | RoHS compliant |
| LABS (PWIS) conformity | VDMA24364-B2-L |

General technical data – Label holder for valve terminals MPA-L

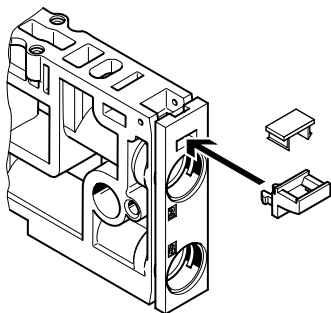

|                |       |       |       |
|----------------|-------|-------|-------|
| Valve size     | 10 mm | 14 mm | 20 mm |
| Size of pack   | 10    |       |       |
| Product weight | 3 g   |       | 5 g   |

 
Materials – Label holder for valve terminals MPA-L

|                        |                   |
|------------------------|-------------------|
| Material label holder  | POM               |
| Note on materials      | RoHS compliant    |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |

Operating and environmental conditions – Label holder for valve terminals MPA-L

|                                |                                |
|--------------------------------|--------------------------------|
| Corrosion resistance class CRC | 4 - Very high corrosion stress |
|--------------------------------|--------------------------------|

General technical data – Label holder with inscription label IBS-6x10 for valve terminals MPA-S



 
|                |                     |                    |
|----------------|---------------------|--------------------|
| Series         | Label holder VMPA14 | Label holder VMPA1 |
| Product weight | 2.7 g               | 1 g                |

Materials – Label holder with inscription label IBS-6x10 for valve terminals MPA-S

|                        |                   |
|------------------------|-------------------|
| Material label holder  | POM               |
| Note on materials      | RoHS compliant    |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |

## Datasheet

### General technical data – Label holder with paper foil label for valve terminals MPA-S

 


|                |                     |                    |
|----------------|---------------------|--------------------|
| Series         | Label holder VMPA14 | Label holder VMPA1 |
| Product weight | 1.5 g               | 1 g                |

### Materials – Label holder with paper foil label for valve terminals MPA-S

|                        |                     |                    |
|------------------------|---------------------|--------------------|
| Series                 | Label holder VMPA14 | Label holder VMPA1 |
| Material label holder  | PP                  | –                  |
| Note on materials      | RoHS compliant      |                    |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L   |                    |

### General technical data – Label holder for terminal CPX



|                |       |
|----------------|-------|
| Width          | 12 mm |
| Height         | 2 mm  |
| Length         | 48 mm |
| Product weight | 5 g   |

 
### Material – Label holder for terminal CPX

|                        |                |
|------------------------|----------------|
| Material label holder  | PP             |
| LABS (PWIS) conformity | VDMA24364-B2-L |

### Operating and environmental conditions – Label holder for terminal CPX

|                     |              |
|---------------------|--------------|
| Ambient temperature | -5 ... 50°C  |
| Storage temperature | -20 ... 70°C |

### General technical data – Label holder for Motion Terminal VTEM



|                |       |
|----------------|-------|
| Product weight | 5.4 g |
|----------------|-------|

### Materials – Label holder for Motion Terminal VTEM

|                        |                   |
|------------------------|-------------------|
| Material label holder  | PP                |
| Note on materials      | RoHS compliant    |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |


### Operating and environmental conditions – Label holder for Motion Terminal VTEM

|                                                 |                               |
|-------------------------------------------------|-------------------------------|
| Corrosion resistance class<br>CRC <sup>1)</sup> | 2 - Moderate corrosion stress |
|-------------------------------------------------|-------------------------------|

1) More information [www.festo.com/x/topic/kbk](http://www.festo.com/x/topic/kbk)


Datasheet

Materials – Label holders for input modules CTSL

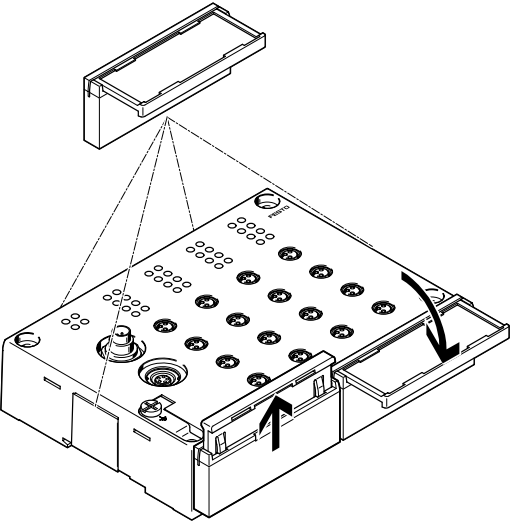

|                        |                |
|------------------------|----------------|
| Material label holder  | Reinforced PA  |
| Material label         | PVC            |
| LABS (PWIS) conformity | VDMA24364-B2-L |

Materials – Label holder for valve terminals VTOC

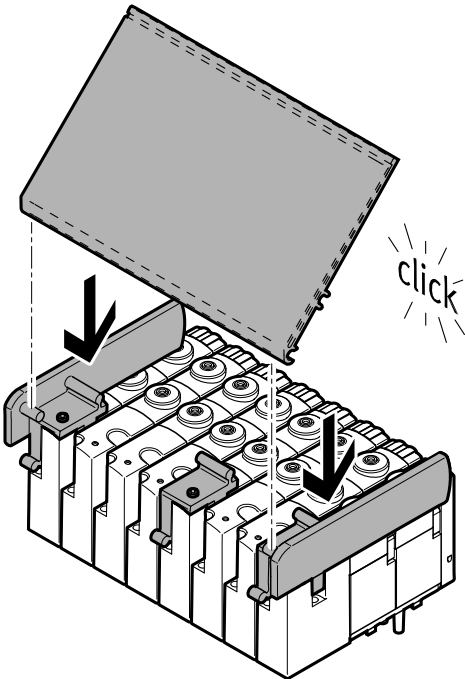

|                        |                |
|------------------------|----------------|
| Material label holder  | PVC            |
| Note on materials      | RoHS compliant |
| LABS (PWIS) conformity | VDMA24364-B2-L |


Operating and environmental conditions – Label holder for valve terminals VTOC

|                                                 |                          |
|-------------------------------------------------|--------------------------|
| Corrosion resistance class<br>CRC <sup>1)</sup> | 1 - Low corrosion stress |
|-------------------------------------------------|--------------------------|

1) More information [www.festo.com/x/topic/kbk](http://www.festo.com/x/topic/kbk)

## Datasheet

### Materials – Label holder for valve terminals VTUG

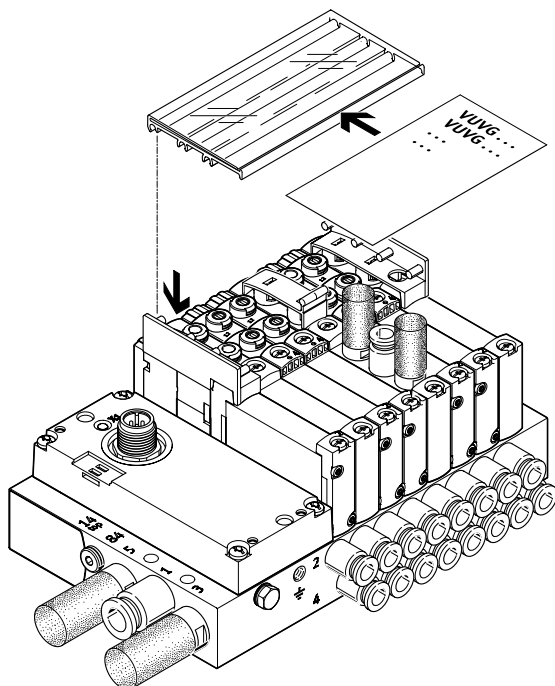

 
|                        |                   |
|------------------------|-------------------|
| Material label holder  | –                 |
| Note on materials      | RoHS compliant    |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |

### Operating and environmental conditions – Label holder for valve terminals VTUG

|                                                 |                               |
|-------------------------------------------------|-------------------------------|
| Corrosion resistance class<br>CRC <sup>1)</sup> | 2 - Moderate corrosion stress |
|-------------------------------------------------|-------------------------------|

1) More information [www.festo.com/x/topic/kbk](http://www.festo.com/x/topic/kbk)

### General technical data – Label holder for manifold sub-bases according to ISO 5599-1, VABV-S1




|                |       |
|----------------|-------|
| Width          | 21 mm |
| Height         | 7 mm  |
| Length         | 42 mm |
| Product weight | 2 g   |

### Materials – Label holder for manifold sub-bases according to ISO 5599-1, VABV-S1

|                        |                   |
|------------------------|-------------------|
| Material label holder  | –                 |
| Material label         | PP                |
| Note on materials      | RoHS compliant    |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |

Datasheet

Materials – Label holder for valve terminals VTSA/VTSA-F

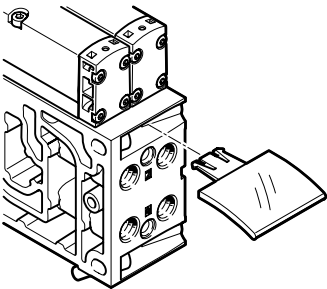


|                        |                   |            |
|------------------------|-------------------|------------|
| Allocation             | Version S2        | Version S6 |
| Material label holder  | PP                |            |
| Note on materials      | RoHS compliant    | –          |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |            |

Operating and environmental conditions – Label holder for valve terminals VTSA/VTSA-F

|                                                 |                         |
|-------------------------------------------------|-------------------------|
| Corrosion resistance class<br>CRC <sup>1)</sup> | 0 - No corrosion stress |
|-------------------------------------------------|-------------------------|

1) More information [www.festo.com/x/topic/kbk](http://www.festo.com/x/topic/kbk)

Materials – Label holders for VSVA valves

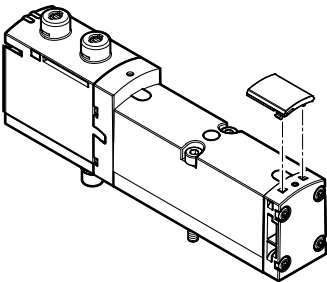


|                        |                   |
|------------------------|-------------------|
| Material label holder  | PP                |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |

Operating and environmental conditions – Label holder for valves VSVA

|                                                 |                         |
|-------------------------------------------------|-------------------------|
| Corrosion resistance class<br>CRC <sup>1)</sup> | 0 - No corrosion stress |
|-------------------------------------------------|-------------------------|

1) More information [www.festo.com/x/topic/kbk](http://www.festo.com/x/topic/kbk)

General technical data – Label holder with additional check boxes for VSVA valves

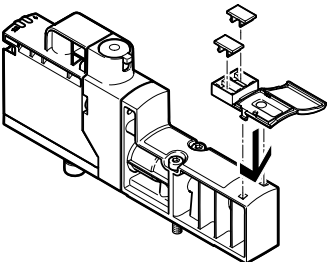


|                |     |
|----------------|-----|
| Product weight | 1 g |
|----------------|-----|

## Datasheet

### Materials – Label holder with additional check boxes for valves VSVA

|                        |                   |
|------------------------|-------------------|
| Material label holder  | PP                |
| Note on materials      | RoHS compliant    |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |

### General technical data – Label holders for valve terminals VTUX, profile 1 incl. holder

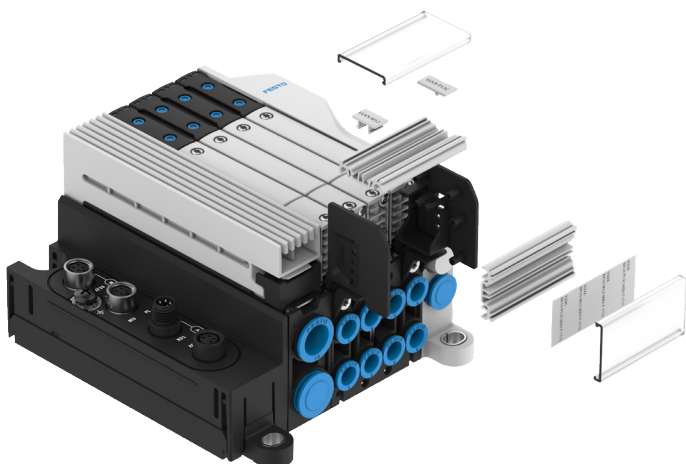

|                                |                                                  |       |
|--------------------------------|--------------------------------------------------|-------|
| Size                           | 1                                                | 2     |
| Max. number of valve positions | 4                                                | 8     |
| Compatible with                | Valve terminal VTUX-A-P; Valve terminal VTUX-A-S |       |
| Max. tightening torque         | 0.5 Nm                                           |       |
| Width                          | 26 mm                                            |       |
| Height                         | 7 mm                                             |       |
| Length                         | 42 mm                                            | 84 mm |
| Size of pack                   | 1                                                |       |
| Product weight                 | 11 g                                             | 16 g  |

### General technical data – Label holders for valve terminals VTUX, profile 3 incl. holder

|                                |                                                  |                         |
|--------------------------------|--------------------------------------------------|-------------------------|
| Size                           | 1                                                | 2                       |
| Max. number of valve positions | 4                                                | 8                       |
| Compatible with                | Valve terminal VTUX-A-P; Valve terminal VTUX-A-S | Valve terminal VTUX-A-S |
| Max. tightening torque         | 0.5 Nm                                           |                         |
| Width                          | 53 mm                                            |                         |
| Height                         | 7 mm                                             |                         |
| Length                         | 42 mm                                            | 84 mm                   |
| Size of pack                   | 1                                                |                         |
| Product weight                 | 13 g                                             | 21 g                    |

### General technical data – Label holders for valve terminals VTUX, individual parts

|                                |                                                        |           |          |
|--------------------------------|--------------------------------------------------------|-----------|----------|
| Designation element            | Profile 1                                              | Profile 3 | Retainer |
| Compatible with                | Valve terminal VTUX-A-P; Valve terminal VTUX-A-S       |           |          |
| Max. number of valve positions | Versions according to customer specifications possible |           |          |
| Max. tightening torque         | 0.5 Nm                                                 |           |          |
| Size                           | 1; 2                                                   |           |          |
| Width                          | 26 mm                                                  | 53 mm     | 26 mm    |
| Height                         | 7 mm                                                   |           |          |
| Length                         | 1,000 mm                                               |           | 10.2 mm  |
| Size of pack                   | 5                                                      |           | 1        |
| Product weight                 | 680 g                                                  | 940 g     | 35 g     |

## Datasheet

**Materials – Label holder for valve terminals VTUG**

|                                                           |                                                                                          |
|-----------------------------------------------------------|------------------------------------------------------------------------------------------|
| Material label holder                                     | Reinforced PA                                                                            |
| Material label                                            | PVC                                                                                      |
| Material screen                                           | PVC                                                                                      |
| Note on materials                                         | RoHS compliant                                                                           |
| LABS (PWIS) conformity                                    | VDMA24364-B1/B2-L                                                                        |
| Suitability for the production of Li-ion batteries        | Suitable for battery production with reduced Cu/Zn/Ni values (F1a)                       |
| Cleanroom suitability, measured according to ISO 14644-14 | Element installed statically, no meaningful evaluation possible according to ISO 14644-1 |


**Operating and environmental conditions – Label holder for valve terminals VTUX**

|                                              |                          |
|----------------------------------------------|--------------------------|
| Ambient temperature                          | -5 ... 50°C              |
| Storage temperature                          | -20 ... 70°C             |
| Corrosion resistance class CRC <sup>1)</sup> | 1 - Low corrosion stress |


1) More information [www.festo.com/x/topic/crc](http://www.festo.com/x/topic/crc)

## Ordering data


Ordering data – Label holder with inscription label IBS-6x10 for valve terminals CPV
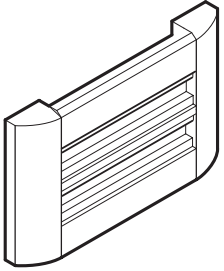
|                                                                                   | Series             | Valve positions   | Product weight | Part no. | Type            |
|-----------------------------------------------------------------------------------|--------------------|-------------------|----------------|----------|-----------------|
|  | Label holder CPV14 | 2 valve positions | 8 g            | 162567   | CPV14-VI-BZ-T-2 |
|                                                                                   | Label holder CPV18 |                   | 9 g            | 163293   | CPV18-VI-BZ-T-2 |
|                                                                                   | Label holder CPV10 |                   | 32 g           | 162560   | CPV10-VI-BZ-T-2 |
|                                                                                   | Label holder CPV14 | 3 valve positions | 9.5 g          | 162568   | CPV14-VI-BZ-T-3 |
|                                                                                   | Label holder CPV18 |                   | 10.5 g         | 163294   | CPV18-VI-BZ-T-3 |
|                                                                                   | Label holder CPV10 |                   | 33 g           | 162561   | CPV10-VI-BZ-T-3 |
|                                                                                   | Label holder CPV14 | 4 valve positions | 11 g           | 162569   | CPV14-VI-BZ-T-4 |
|                                                                                   | Label holder CPV18 |                   | 12 g           | 163295   | CPV18-VI-BZ-T-4 |
|                                                                                   | Label holder CPV10 |                   | 34 g           | 162562   | CPV10-VI-BZ-T-4 |
|                                                                                   | Label holder CPV14 | 5 valve positions | 12.5 g         | 162570   | CPV14-VI-BZ-T-5 |
|                                                                                   | Label holder CPV18 |                   | 13.5 g         | 163296   | CPV18-VI-BZ-T-5 |
|                                                                                   | Label holder CPV10 |                   | 35 g           | 162563   | CPV10-VI-BZ-T-5 |
|                                                                                   | Label holder CPV14 | 6 valve positions | 14 g           | 162571   | CPV14-VI-BZ-T-6 |
|                                                                                   | Label holder CPV18 |                   | 16 g           | 163297   | CPV18-VI-BZ-T-6 |
|                                                                                   | Label holder CPV10 |                   | 36 g           | 162564   | CPV10-VI-BZ-T-6 |
|                                                                                   | Label holder CPV14 | 7 valve positions | 15.5 g         | 162572   | CPV14-VI-BZ-T-7 |
|                                                                                   | Label holder CPV18 |                   | 17.5 g         | 163298   | CPV18-VI-BZ-T-7 |
|                                                                                   | Label holder CPV10 |                   | 37 g           | 162565   | CPV10-VI-BZ-T-7 |
|                                                                                   | Label holder CPV14 | 8 valve positions | 17 g           | 162573   | CPV14-VI-BZ-T-8 |
|                                                                                   | Label holder CPV18 |                   | 20 g           | 163299   | CPV18-VI-BZ-T-8 |
|                                                                                   | Label holder CPV10 |                   | 38 g           | 162566   | CPV10-VI-BZ-T-8 |


Ordering data – Label holder with inspection window for valve terminals CPV

 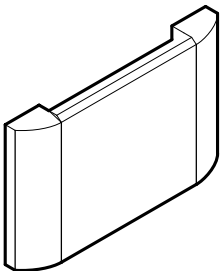
|                                                                                     | Series             | Valve positions   | Product weight | Part no. | Type            |
|-------------------------------------------------------------------------------------|--------------------|-------------------|----------------|----------|-----------------|
|  | Label holder CPV14 | 2 valve positions |                | 194073   | CPV14-VI-ST-T-2 |
|                                                                                     | Label holder CPV10 |                   | 11 g           | 194066   | CPV10-VI-ST-T-2 |
|                                                                                     | Label holder CPV18 |                   | 17 g           | 194080   | CPV18-VI-ST-T-2 |
|                                                                                     | Label holder CPV10 | 3 valve positions | 14 g           | 194067   | CPV10-VI-ST-T-3 |
|                                                                                     | Label holder CPV14 |                   | 18 g           | 194074   | CPV14-VI-ST-T-3 |
|                                                                                     | Label holder CPV18 |                   | 23 g           | 194081   | CPV18-VI-ST-T-3 |
|                                                                                     | Label holder CPV10 | 4 valve positions | 17 g           | 194068   | CPV10-VI-ST-T-4 |
|                                                                                     | Label holder CPV14 |                   | 22 g           | 194075   | CPV14-VI-ST-T-4 |
|                                                                                     | Label holder CPV18 |                   | 29 g           | 194082   | CPV18-VI-ST-T-4 |
|                                                                                     | Label holder CPV10 | 5 valve positions | 20 g           | 194069   | CPV10-VI-ST-T-5 |
|                                                                                     | Label holder CPV14 |                   | 25 g           | 194076   | CPV14-VI-ST-T-5 |
|                                                                                     | Label holder CPV18 |                   | 35 g           | 194083   | CPV18-VI-ST-T-5 |
|                                                                                     | Label holder CPV10 | 6 valve positions | 23 g           | 194070   | CPV10-VI-ST-T-6 |
|                                                                                     | Label holder CPV18 |                   | 41 g           | 194084   | CPV18-VI-ST-T-6 |
|                                                                                     | Label holder CPV14 |                   | 53 g           | 194077   | CPV14-VI-ST-T-6 |
|                                                                                     | Label holder CPV10 | 7 valve positions | 24 g           | 194071   | CPV10-VI-ST-T-7 |
|                                                                                     | Label holder CPV18 |                   | 47 g           | 194085   | CPV18-VI-ST-T-7 |
|                                                                                     | Label holder CPV14 |                   | 59 g           | 194078   | CPV14-VI-ST-T-7 |
|                                                                                     | Label holder CPV10 | 8 valve positions | 29 g           | 194072   | CPV10-VI-ST-T-8 |
|                                                                                     | Label holder CPV18 |                   | 53 g           | 194086   | CPV18-VI-ST-T-8 |
|                                                                                     | Label holder CPV14 |                   | 63 g           | 194079   | CPV14-VI-ST-T-8 |


Ordering data – Label holder for valve terminals CPV-SC

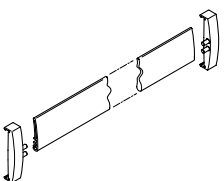
|                                                                                     | Series              | Valve positions   | Part no. | Type        |
|-------------------------------------------------------------------------------------|---------------------|-------------------|----------|-------------|
|  | Label holder CPVSC1 | 2 valve positions | 547395   | CPVSC1-ST-2 |


## Ordering data
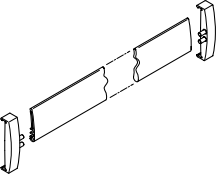
| Ordering data – Label holder for valve terminals CPV-SC                          |                     |                    |          |              |
|----------------------------------------------------------------------------------|---------------------|--------------------|----------|--------------|
|                                                                                  | Series              | Valve positions    | Part no. | Type         |
|  | Label holder CPVSC1 | 3 valve positions  | 547396   | CPVSC1-ST-3  |
|                                                                                  |                     | 4 valve positions  | 527631   | CPVSC1-ST-4  |
|                                                                                  |                     | 5 valve positions  | 547397   | CPVSC1-ST-5  |
|                                                                                  |                     | 6 valve positions  | 547398   | CPVSC1-ST-6  |
|                                                                                  |                     | 7 valve positions  | 547399   | CPVSC1-ST-7  |
|                                                                                  |                     | 8 valve positions  | 527633   | CPVSC1-ST-8  |
|                                                                                  |                     | 9 valve positions  | 547400   | CPVSC1-ST-9  |
|                                                                                  |                     | 10 valve positions | 547401   | CPVSC1-ST-10 |
|                                                                                  |                     | 11 valve positions | 547402   | CPVSC1-ST-11 |
|                                                                                  |                     | 12 valve positions | 527635   | CPVSC1-ST-12 |
|                                                                                  |                     | 13 valve positions | 547403   | CPVSC1-ST-13 |
|                                                                                  |                     | 14 valve positions | 547404   | CPVSC1-ST-14 |
|                                                                                  |                     | 15 valve positions | 547405   | CPVSC1-ST-15 |
|                                                                                  |                     | 16 valve positions | 527637   | CPVSC1-ST-16 |

| Ordering data – Label holder for valve terminals MPA-L                           |                    |            |              |          |                |
|----------------------------------------------------------------------------------|--------------------|------------|--------------|----------|----------------|
|                                                                                  | Series             | Valve size | Size of pack | Part no. | Type           |
|  | Label holder VMPAL | 10 mm      | 10           | 561109   | VMPAL-ST-AP-10 |
|                                                                                  |                    | 14 mm      |              | 561112   | VMPAL-ST-AP-14 |
|                                                                                  |                    | 20 mm      |              | 561115   | VMPAL-ST-AP-20 |

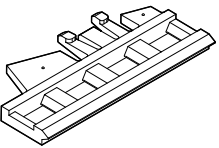
| Ordering data – Label holder with inscription label IBS-6x10 for valve terminals MPA-S |                     |                   |          |               |
|----------------------------------------------------------------------------------------|---------------------|-------------------|----------|---------------|
|                                                                                        | Series              | Valve positions   | Part no. | Type          |
|      | Label holder VMPA14 | 4 valve positions | 8085997  | VMPA14-ST-2-4 |
|                                                                                        | Label holder VMPA1  |                   | 544384   | VMPA1-ST-2-4  |
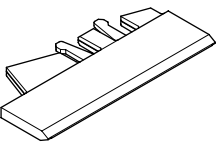
| Ordering data – Label holder with paper foil label for valve terminals MPA-S       |                     |                   |          |               |
|------------------------------------------------------------------------------------|---------------------|-------------------|----------|---------------|
|                                                                                    | Series              | Valve positions   | Part no. | Type          |
|  | Label holder VMPA14 | 4 valve positions | 8085996  | VMPA14-ST-1-4 |
|                                                                                    | Label holder VMPA1  |                   | 533362   | VMPA1-ST-1-4  |

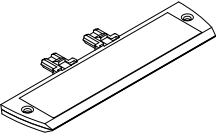
| Ordering data – Label holder for CPX terminal                                      |                  |          |          |
|------------------------------------------------------------------------------------|------------------|----------|----------|
|                                                                                    | Series           | Part no. | Type     |
|  | Label holder CPX | 536593   | CPX-ST-1 |

## Ordering data


## Ordering data – Label holder for Motion Terminal VTEM
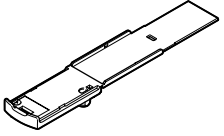
|                                                                                   | Series            | Size of pack | Part no. | Type       |
|-----------------------------------------------------------------------------------|-------------------|--------------|----------|------------|
|  | Label holder ASCF | 4            | 8047501  | ASCF-H-P11 |


## Ordering data – Label holder for input modules CTSI
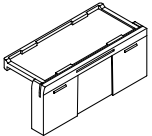
|                                                                                   | Series            | Valve positions | Product weight | Part no. | Type      |
|-----------------------------------------------------------------------------------|-------------------|-----------------|----------------|----------|-----------|
|  | Label holder ASCF | None            |                | 547473   | ASCF-H-E2 |


## Ordering data – Label holder for valve terminals VTOC

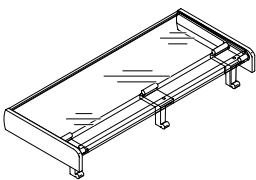
|                                                                                    | Series            | Valve positions    | Product weight | Part no. | Type          |
|------------------------------------------------------------------------------------|-------------------|--------------------|----------------|----------|---------------|
|  | Label holder ASCF | 3 valve positions  | 9.9 g          | 565571   | ASCF-H-L2-3V  |
|                                                                                    |                   | 4 valve positions  | 11.5 g         | 565572   | ASCF-H-L2-4V  |
|                                                                                    |                   | 5 valve positions  | 13.1 g         | 565573   | ASCF-H-L2-5V  |
|                                                                                    |                   | 6 valve positions  | 14.7 g         | 565574   | ASCF-H-L2-6V  |
|                                                                                    |                   | 7 valve positions  | 17.2 g         | 565575   | ASCF-H-L2-7V  |
|                                                                                    |                   | 8 valve positions  | 18.8 g         | 565576   | ASCF-H-L2-8V  |
|                                                                                    |                   | 9 valve positions  | 20.4 g         | 565577   | ASCF-H-L2-9V  |
|                                                                                    |                   | 10 valve positions | 22 g           | 565578   | ASCF-H-L2-10V |
|                                                                                    |                   | 11 valve positions | 23.6 g         | 565579   | ASCF-H-L2-11V |
|                                                                                    |                   | 12 valve positions | 25.2 g         | 565580   | ASCF-H-L2-12V |
|                                                                                    |                   | 13 valve positions | 27.7 g         | 565581   | ASCF-H-L2-13V |
|                                                                                    |                   | 14 valve positions | 29.3 g         | 565582   | ASCF-H-L2-14V |
|                                                                                    |                   | 15 valve positions | 30.9 g         | 565583   | ASCF-H-L2-15V |
|                                                                                    |                   | 16 valve positions | 32.5 g         | 565584   | ASCF-H-L2-16V |
|                                                                                    |                   | 17 valve positions | 34.1 g         | 565585   | ASCF-H-L2-17V |
|                                                                                    |                   | 18 valve positions | 35.7 g         | 565586   | ASCF-H-L2-18V |
|                                                                                    |                   | 19 valve positions | 38.2 g         | 565587   | ASCF-H-L2-19V |
|                                                                                    |                   | 20 valve positions | 39.8 g         | 565588   | ASCF-H-L2-20V |
|                                                                                    |                   | 21 valve positions | 41.4 g         | 565589   | ASCF-H-L2-21V |
|                                                                                    |                   | 22 valve positions | 43 g           | 565590   | ASCF-H-L2-22V |
|                                                                                    |                   | 23 valve positions | 44.6 g         | 565591   | ASCF-H-L2-23V |
|                                                                                    |                   | 24 valve positions | 46.2 g         | 565592   | ASCF-H-L2-24V |

## Ordering data – Label holder for valve terminals VTUG

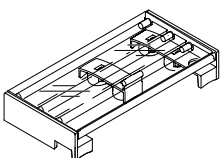
|                                                                                     | Series             | Size    | Valve positions    | Product weight | Part no. | Type             |
|-------------------------------------------------------------------------------------|--------------------|---------|--------------------|----------------|----------|------------------|
|  | Label holder AS-CF | Size 10 | 4 valve positions  | 10 g           | 573453   | ASCF-H-L1-10-4V  |
|                                                                                     |                    |         | 5 valve positions  | 11.25 g        | 573454   | ASCF-H-L1-10-5V  |
|                                                                                     |                    |         | 6 valve positions  | 12.5 g         | 573455   | ASCF-H-L1-10-6V  |
|                                                                                     |                    |         | 7 valve positions  | 13.75 g        | 573456   | ASCF-H-L1-10-7V  |
|                                                                                     |                    |         | 8 valve positions  | 15 g           | 573457   | ASCF-H-L1-10-8V  |
|                                                                                     |                    |         | 9 valve positions  | 16.25 g        | 573458   | ASCF-H-L1-10-9V  |
|                                                                                     |                    |         | 10 valve positions | 17.5 g         | 573459   | ASCF-H-L1-10-10V |
|                                                                                     |                    |         | 12 valve positions | 20 g           | 573460   | ASCF-H-L1-10-12V |

## Ordering data

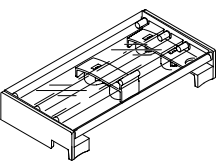
| Ordering data – Label holder for valve terminals VTUG                            |                    |               |                    |                |          |                  |
|----------------------------------------------------------------------------------|--------------------|---------------|--------------------|----------------|----------|------------------|
|                                                                                  | Series             | Size          | Valve positions    | Product weight | Part no. | Type             |
|  | Label holder AS-CF | Size 10       | 16 valve positions | 25 g           | 573461   | ASCF-H-L1-10-16V |
|                                                                                  |                    |               | 20 valve positions | 30 g           | 573462   | ASCF-H-L1-10-20V |
|                                                                                  |                    |               | 24 valve positions | 35 g           | 573463   | ASCF-H-L1-10-24V |
|                                                                                  |                    | Size 14       | 4 valve positions  | 12.2 g         | 573511   | ASCF-H-L1-14-4V  |
|                                                                                  |                    |               | 5 valve positions  | 14 g           | 573512   | ASCF-H-L1-14-5V  |
|                                                                                  |                    |               | 6 valve positions  | 15.8 g         | 573513   | ASCF-H-L1-14-6V  |
|                                                                                  |                    |               | 7 valve positions  | 17.6 g         | 573514   | ASCF-H-L1-14-7V  |
|                                                                                  |                    |               | 8 valve positions  | 19.4 g         | 573515   | ASCF-H-L1-14-8V  |
|                                                                                  |                    |               | 9 valve positions  | 21.2 g         | 573516   | ASCF-H-L1-14-9V  |
|                                                                                  |                    |               | 10 valve positions | 23 g           | 573518   | ASCF-H-L1-14-10V |
|                                                                                  |                    |               | 12 valve positions | 26.6 g         | 573519   | ASCF-H-L1-14-12V |
|                                                                                  |                    |               | 16 valve positions | 33.8 g         | 573520   | ASCF-H-L1-14-16V |
|                                                                                  |                    |               | 20 valve positions | 41 g           | 573521   | ASCF-H-L1-14-20V |
|                                                                                  |                    |               | 24 valve positions | 48.2 g         | 573522   | ASCF-H-L1-14-24V |
|                                                                                  |                    | Size 18/18 mm | 4 valve positions  | 13.6 g         | 8004928  | ASCF-H-L1-18-4V  |
|                                                                                  |                    |               | 5 valve positions  | 15.75 g        | 8004929  | ASCF-H-L1-18-5V  |
|                                                                                  |                    |               | 6 valve positions  | 17.9 g         | 8004930  | ASCF-H-L1-18-6V  |
|                                                                                  |                    |               | 7 valve positions  | 20.05 g        | 8004931  | ASCF-H-L1-18-7V  |
|                                                                                  |                    |               | 8 valve positions  | 22.2 g         | 8004932  | ASCF-H-L1-18-8V  |
|                                                                                  |                    |               | 9 valve positions  | 24.35 g        | 8004933  | ASCF-H-L1-18-9V  |
|                                                                                  |                    |               | 10 valve positions | 26.5 g         | 8004934  | ASCF-H-L1-18-10V |
|                                                                                  |                    |               | 12 valve positions | 30.8 g         | 8004935  | ASCF-H-L1-18-12V |
|                                                                                  |                    |               | 16 valve positions | 39.4 g         | 8004936  | ASCF-H-L1-18-16V |
|                                                                                  |                    |               | 20 valve positions | 48 g           | 8004937  | ASCF-H-L1-18-20V |
|                                                                                  |                    |               | 24 valve positions | 56.6 g         | 8004938  | ASCF-H-L1-18-24V |
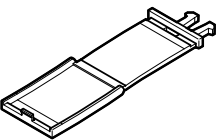
| Ordering data – Label holder for manifold sub-bases according to ISO 5599-1, VABV-S1 |                    |                                 |                                      |              |          |           |
|--------------------------------------------------------------------------------------|--------------------|---------------------------------|--------------------------------------|--------------|----------|-----------|
|                                                                                      | Series             | Designation element             | Allocation                           | Size of pack | Part no. | Type      |
|    | Label holder AS-CF | Label holder for manifold block | Version S1 (round cylinder ISO 6432) | 5            | 8037164  | ASCF-M-S1 |

## Ordering data
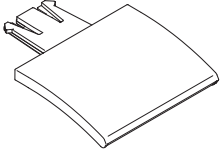
| Ordering data – Label holder for valve terminals VTSA/VTSA-F                      |                   |            |          |               |                    |
|-----------------------------------------------------------------------------------|-------------------|------------|----------|---------------|--------------------|
|                                                                                   | Series            | Allocation | Size     | Part no.      | Type               |
|  | Label holder ASCF | Version S6 | Standard | <b>540889</b> | <b>ASCF-M-S6</b>   |
|                                                                                   |                   | Version S2 | Size 2   | <b>562577</b> | <b>ASCF-M-S2-2</b> |

| Ordering data – Label holder for VSVA valves                                      |                   |            |                           |               |                  |
|-----------------------------------------------------------------------------------|-------------------|------------|---------------------------|---------------|------------------|
|                                                                                   | Series            | Allocation | Designation element       | Part no.      | Type             |
|  | Label holder ASCF | Version S6 | Label holder, transparent | <b>540888</b> | <b>ASCF-T-S6</b> |
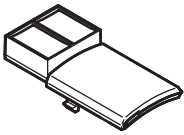
| Ordering data – Label holder with additional check boxes for valves VSVA           |                   |            |                           |                |                    |
|------------------------------------------------------------------------------------|-------------------|------------|---------------------------|----------------|--------------------|
|                                                                                    | Series            | Allocation | Designation element       | Part no.       | Type               |
|  | Label holder ASCF | Version S6 | Label holder, transparent | <b>8106532</b> | <b>ASCF-T-S6-Z</b> |

| Ordering data – Label holder for valve terminals VTUX, retainer                     |                   |      |                                                        |                |                  |
|-------------------------------------------------------------------------------------|-------------------|------|--------------------------------------------------------|----------------|------------------|
|                                                                                     | Series            | Size | Max. number of valve positions                         | Part no.       | Type             |
|  | Label holder ASCF | 1, 2 | Versions according to customer specifications possible | <b>8207664</b> | <b>ASCF-R-XA</b> |

| Ordering data – Label holder for valve terminals VTUX, profile 1                    |                   |      |                                                        |                |                        |
|-------------------------------------------------------------------------------------|-------------------|------|--------------------------------------------------------|----------------|------------------------|
|                                                                                     | Series            | Size | Max. number of valve positions                         | Part no.       | Type                   |
|  | Label holder ASCF | 1, 2 | Versions according to customer specifications possible | <b>8207665</b> | <b>ASCF-P1-XA-1000</b> |


## Ordering data

| Ordering data – Label holder for valve terminals VTUX, profile 3                 |                   |      |                                                        |                |                        |
|----------------------------------------------------------------------------------|-------------------|------|--------------------------------------------------------|----------------|------------------------|
|                                                                                  | Series            | Size | Max. number of valve positions                         | Part no.       | Type                   |
|  | Label holder ASCF | 1, 2 | Versions according to customer specifications possible | <b>8207666</b> | <b>ASCF-P3-XA-1000</b> |

| Ordering data – Label holder for valve terminals VTUX, profile 1 incl. retainer  |                   |      |                                |                |                        |
|----------------------------------------------------------------------------------|-------------------|------|--------------------------------|----------------|------------------------|
|                                                                                  | Series            | Size | Max. number of valve positions | Part no.       | Type                   |
|  | Label holder ASCF | 1    | 4                              | <b>8207652</b> | <b>ASCF-RP1-XA-42</b>  |
|                                                                                  |                   |      | 8                              | <b>8207655</b> | <b>ASCF-RP1-XA-84</b>  |
|                                                                                  |                   | 2    | 4                              | <b>8207658</b> | <b>ASCF-RP1-XA-50</b>  |
|                                                                                  |                   |      | 8                              | <b>8207661</b> | <b>ASCF-RP1-XA-100</b> |

| Ordering data – Label holder for valve terminals VTUX, profile 3 incl. retainer    |                   |      |                                |                |                        |
|------------------------------------------------------------------------------------|-------------------|------|--------------------------------|----------------|------------------------|
|                                                                                    | Series            | Size | Max. number of valve positions | Part no.       | Type                   |
|  | Label holder ASCF | 1    | 4                              | <b>8207653</b> | <b>ASCF-RP3-XA-42</b>  |
|                                                                                    |                   |      | 8                              | <b>8207656</b> | <b>ASCF-RP3-XA-84</b>  |
|                                                                                    |                   | 2    | 4                              | <b>8207659</b> | <b>ASCF-RP3-XA-50</b>  |
|                                                                                    |                   |      | 8                              | <b>8207662</b> | <b>ASCF-RP3-XA-100</b> |

## Accessories
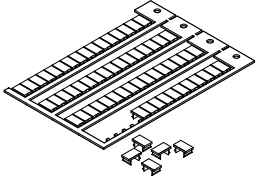
| Inscription labels                                                                |           |              |                |                           |
|-----------------------------------------------------------------------------------|-----------|--------------|----------------|---------------------------|
|                                                                                   | Size      | Size of pack | Part no.       | Type                      |
|  | 10x6 mm   |              | <b>18576</b>   | <b>IBS-6X10</b>           |
|                                                                                   | 6x12.5 mm | 24           | <b>8087174</b> | <b>ASLR-L-X4-612-P240</b> |