


# Magswitch AR Series

FESTO

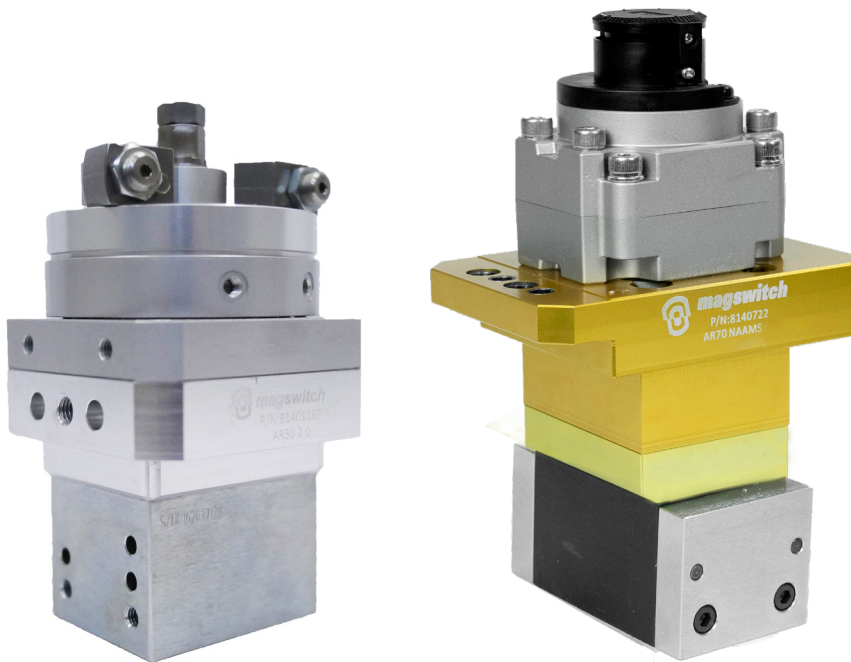

## Customizable to any Geometry

### Features

- Compact single magnet design
- Customizable contact surface
- Maximum power to weight ratio
- Saves energy - 90% less air
- Fail-safe operation
- Larger air ports (G1/8)
- Symmetrical NAAMS mounting

Magswitch AR tools are some of the most versatile grippers in our lineup! These compact tools pack a high power to weight ratio to handle any size application. With customizable pole shoes, the AR series can handle any geometry you throw at it.

### High Heat Series

Our AR Series is available in high temperature versions. They are capable of handling up to 742° Fahrenheit (350° Celsius) and can be used in Hot Stamping applications.


### Applications

Bin Picking, Assembly, Body-In-White, Pressure Vessel Fabrication, Press Line, Hot Stamping

# Magswitch AR Series

	AR 50 2.0	AR 70 NAAMS
Part #	23283594	23283599
Max Breakaway*	489 lbs (222 kg)	960 lbs (435 kg)
Height	6.06 in (152.1 mm)	10.1 in (255.8 mm)
Width	3.28 in (83.3 mm)	4.3 in (108 mm)
Length	3.28 in (83.3 mm)	6.1 in (154.5 mm)
Weight	4.9 lbs (2.2 kg)	14.92 lbs (6.8 kg)

\* This does not apply to all conditions. See spec sheets for more performance data.

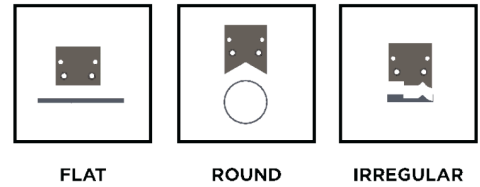

FLAT

ROUND

IRREGULAR

## Applications

Bin Picking, Assembly, Body-In-White, Pressure Vessel Fabrication, Press Line, Hot Stamping



Bin Picking (AR50 EOAT Kit w/Armor with multiple applications)



Body-In-White Material Handling

## Product Accessories

**23283595:** AR50 2.0 Standard Pole Shoe Kit