



# Clamping module EV-25-4

Part number: 150684

FESTO

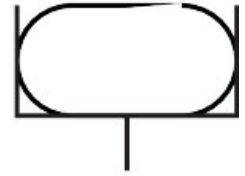

## Data sheet

 General operating condition

| Feature                | Value                                     |
|------------------------|---|
| Stroke                 | 4 mm                                      |
| Clamping surface       | Ø 25                                      |
| Mounting position      | optional                                  |
| Mode of operation      | Single-acting                             |
| Symbol                 | 00991208                                  |
| Operating pressure     | ≤0.6 MPa                                  |
| Operating pressure     | ≤6 bar                                    |
| Operating pressure     | ≤87 psi                                   |
| Operating medium       | Compressed air to ISO 8573-1:2010 [7:-:-] |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L                         |
| Ambient temperature    | -10 °C ... 40 °C                          |
| Product weight         | 24 g                                      |
| Type of mounting       | With through-hole                         |
| Pneumatic connection   | M3  |
| Material housing       | Die-cast aluminium                        |
| Material membrane      | TPE-U(PU)                                 |