


# Round cylinders DSNU-S-..., DSNU-...

FESTO

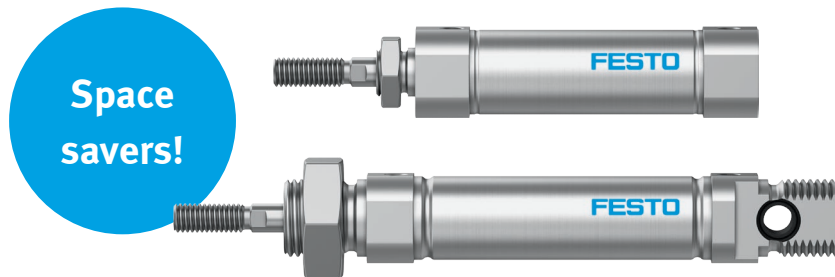

## Ideal for small spaces!

### Highlights

- Space saving for compact machine design
- Easy mounting in confined spaces
- Time-saving assembly through PPS self-adjusting cushioning
- Slimmer and shorter than ever: the DSNU-S
- Extremely durable, also thanks to low-wear materials
- Easy identification and reordering with the Festo Product Key

ISO standards-based DSNU or the smaller and even slimmer DSNU-S? The round cylinder DSNU is always a solid choice when it comes to performance and compact dimensions. Its universal variants make it ideal in applications where low friction, chemical resistance or corrosion resistance are required.

#### Suitable for all-round use: DSNU as an ISO standards-based version

Equipped for all eventualities, for example with the swivel bearing on the end cap. Perfect for corresponding applications. And suitable for all-round use thanks to the large number of variants in the modular system.

#### When space is tight: the DSNU-S

The DSNU-S, our counterpart to the standards-based cylinder, is an even slimmer and shorter variant for even greater space savings.

#### Commissioning made easy


Thanks to PPS cushioning. Perfect cushioning every time, without the need for adjustment. Simple, fast, space-saving and tamper-proof. The stand-out feature of the proximity sensor SDBT-MSX is its auto teach-in for extremely easy commissioning, even in very confined spaces.

#### Long service life

The chosen materials and precision manufacturing make the DSNU variants durable and robust. And by using identical parts in both variants, pricing remains attractive.


# Round cylinders DSNU-S-..., DSNU-...

## Features at a glance

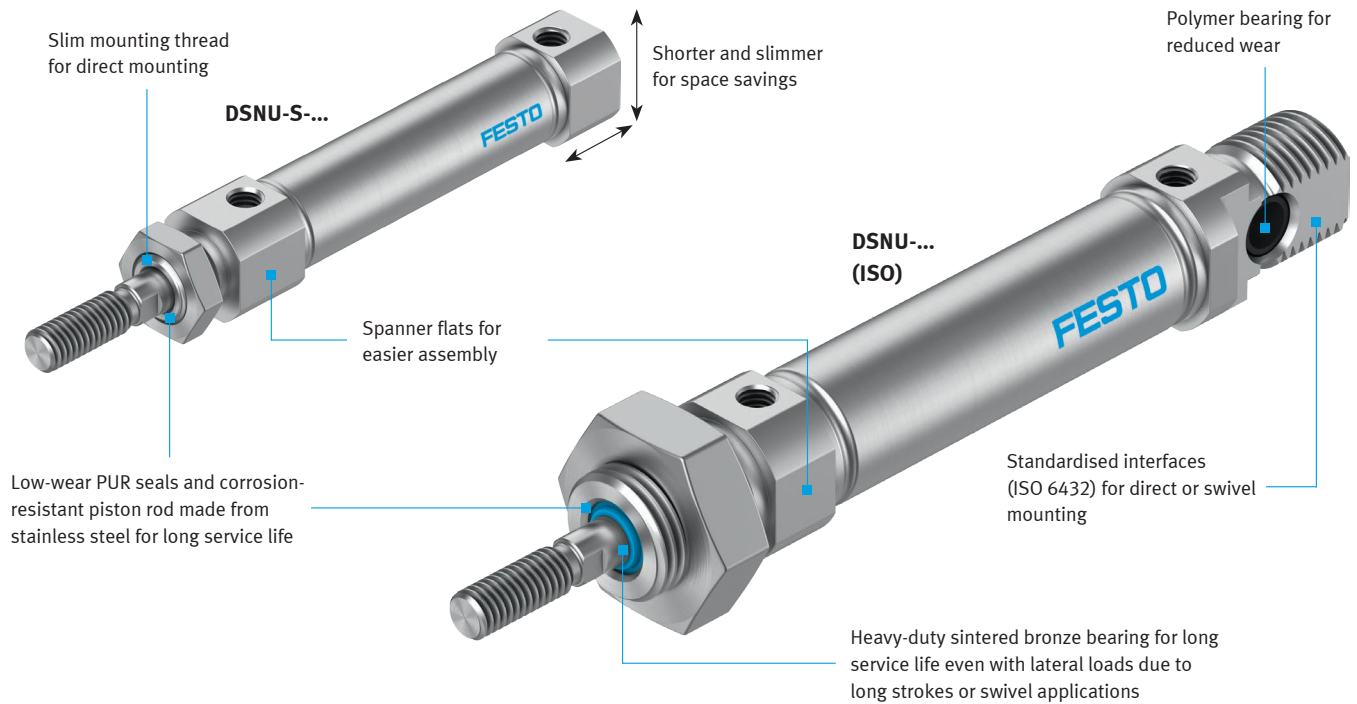

## Slimmer and shorter for more space savings – the DSNU-S-...

Size	8	12	16 ...-P	16 ...-PPS	20	25
BF	8	8	8		13	13
ZJ+	58	60	60	70	76	81
KV	11	14	14		24	24
BE	M8	M10	M10		M20	M20

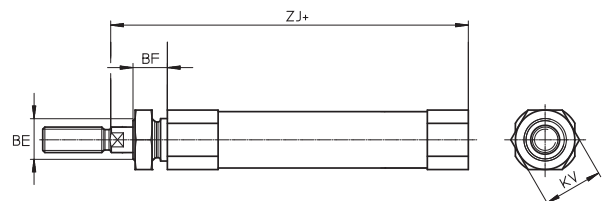

### The space-optimised DSNU-S

Up to 3.5 cm shorter  
Up to 40% slimmer

#### Available variants

- Nominal size Ø 8 ... 25 mm
- Max. stroke 200 mm
- P/PPS cushioning
- Standard strokes and x lengths

#### Mounting thread

- Ø 8 ... 16 on the bearing cap
- Ø 20/25 additionally on the end cap

### The universal DSNU-... (ISO)

Further mounting options

- Swivelling rod eye

#### Further variants

- Nominal size Ø 32 ... 63 mm
- Stroke > 200 mm
- PPV
- Special variants (S2, S6, etc.)

### Easy commissioning

with the new proximity sensor SDBT-MSX even in difficult-to-access installation locations thanks to auto teach-in.



★ **Festo core product range** covers 80% of your automation tasks

**Worldwide:** always in stock

**Superb:** Festo quality at an attractive price

**Easy:** just a few clicks to place an order online

**Fast:** usually ready for dispatch from the Festo factory in 24 hours

[www.festo.com](http://www.festo.com)