


Compact cylinder ADN-...-C (ISO)

FESTO

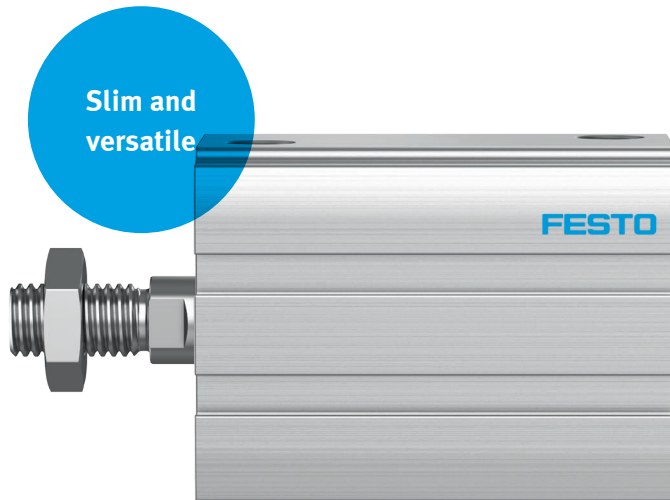

Newly designed output

Highlights

- Weight-optimised
- Space-saving
- Fast and reliable delivery, even in large quantities

When space is tight, when saving every gram counts and when only the most essential features are required, the ADN-...C is the perfect fit. Its sturdy design to ISO and more than 350 variants in a wide range of sizes, lengths and cushioning options make it an extremely attractive option for many applications.

Extremely lightweight – and reduced to the essentials

The double-acting cylinder ADN-...C has a fixed cushioning plate, a piston rod with female thread and can be directly mounted. It is also efficient, precise, durable and attractive and conforms to ISO, even in its lightest version. And installing proximity sensors like the SMT or SDBT is child's play thanks to its slots.

With self-adjusting cushioning PPS

By selecting self-adjusting cushioning for nominal size 20 and above, you gain the following benefits all at once: load-adapted cushioning without the need for space-consuming clearance for adjustment, tamper-proof adjustment since there are no adjusting screws that can be altered, and less noise generation since the piston advances gently into the end positions.

Compact cylinder ADN-...-C (ISO)

The features at a glance

Time-saving

Self-adjusting cushioning (PPS)

Easy to interchange

For standard sizes to ISO 21287: weight-reduced

Fast access to all product data thanks to lasered data matrix code


Easy to assemble
Markings for proximity sensor positions

As needed

Wide choice of variants delivered quickly


Space-saving

Streamlined outer contour for tight mounting conditions

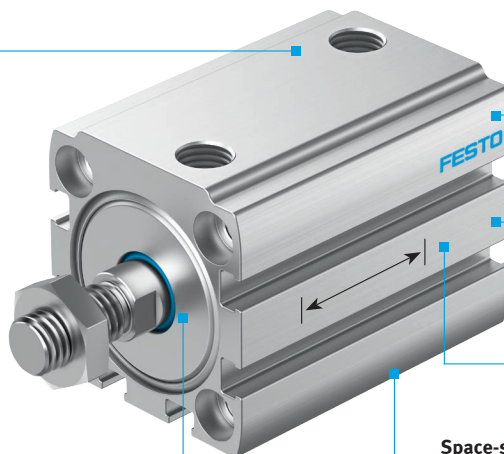


The most important sizes in compliance with ISO 21287

∅	12	16	20	25	32	40	50	63	80
A	27	29	34.5	38.5	45	53	63	75	93
B	27.5	30	35.5	39.5	47	55	65	77.5	95.5
C	35	35	37	39	44	45	45	49	54
E	16	18	22	26	32.5	38	46.5	56.5	72

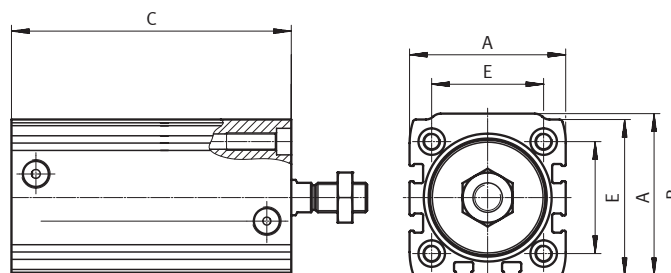

Cushioning variants available in the series

	12	16	20	25	32	40	50	63	80
5	p	p	P/PPS	P/PPS	P/PPS	P/PPS	–	–	–
10	p	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
15	p	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
20	p	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
25	p	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
30	p	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
35	p	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
40	p	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
50	p	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
60	p	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
70	–	p	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS
80	–	–	–	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS	P/PPS

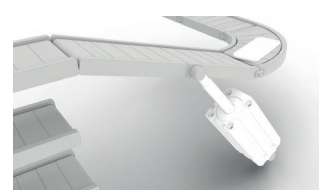

Perfect for sliding and pushing tasks, even in tight spaces

★ Festo core product range

covers 80% of your automation tasks

Worldwide: always in stock

Superb: Festo quality at an attractive price

Easy: just a few clicks to place an order online

Fast: usually ready for dispatch from the Festo factory in 24 hours

www.festo.com