


Hoses - bulk packs and colour variants

FESTO

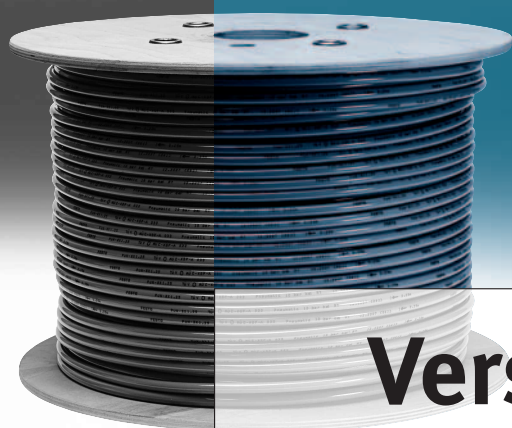

Versatile

Now even more convenient and with more variations: new container sizes and hose colours. All in all, even greater convenience when purchasing hoses, even more attractive prices, even more variants and even more environmentally friendly.

Attractively priced

With the new bulk packs you only pay for one set of packaging. It's practical too: just one action and work can begin!

Tough

Thanks to a new wooden design: The hose reels are robust, don't bend, can be stacked and are resistant to moisture.

Even more colours

They are not only ideal for customising according to your corporate design, but also for more complex installations as different cables can be colour-coded.

Doubly environmentally friendly duo

Clever disposable bulk packs reduce waste packaging. The new corrugated cardboard boxes for standard containers are made out of 100% recycled materials and are twice as environmentally friendly!

Even more individuality: modular hose products

For orders of over 3000 metres you can customise your hoses – e.g. with print, with a broader range of colours, with other container sizes ... Find out more!



Attractive



Robust



Environmentally friendly

413.1.PSI →

Product Short Information

Hoses - bulk packs and colour variants

Colours – Overview

Bulk pack	
PEN	Blue, black, natural, silver
PAN	Blue, black, silver
PUN	Blue, black, silver
PUN-E	Blue, black, silver
PUN-H	Blue, black, natural, silver

Standard pack (50 m)

PEN	Blue, black, natural, silver, green, yellow, red
PAN	Blue, black, natural, silver, green, yellow, red
PAN-R	Silver
PUN	Blue, black, silver, green, yellow, red
PUN-E	Blue, black, silver
PUN-H	Blue, black, natural, silver, green, yellow, red
PUN-VO	Blue, black, natural, silver, green, yellow, red, brown, white
PUN-VO-B	Blue, black, natural, silver, green, yellow, red, brown, white
PLN	Blue, black, natural, silver, red
PFAN	natural

Additional colours are available in the modular product system for individual hoses.


Sizes – Overview

7 different diameters from 3 to 16 mm, standard O.D.tubing


Nominal diameter [mm]	Size [m]
Sizes 3, 4, 6	--> 500
Size 8	--> 400
Size 10	--> 300
Size 12	--> 200
Size 16	--> 100

Additional container sizes are available for modular product systems for individual hoses

The reel - dimensions for storage

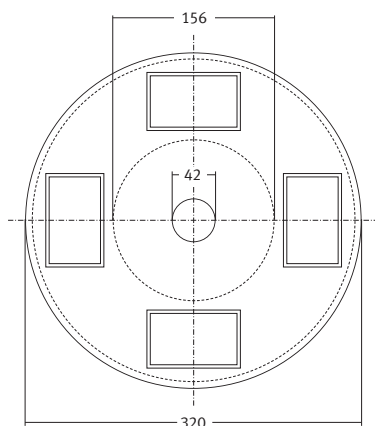

600 mm Flange outer diameter
300 mm Core diameter

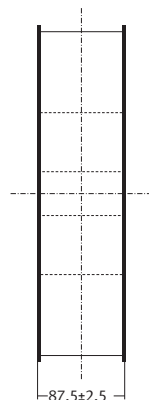

130 mm/260 mm width

Also available in bulk packs:

Quick Star and threaded fittings

In bulk packs with up to ‘

100 pieces

- QS fittings

- Adapter D, E



- Blanking plug B



Further information:

Get more information from the constantly updated download area at www.festo.com, or ask for more information from the Festo Info Service.

Free tube selection software and media-resistance information:

Available in the download area and on the CD-ROM of the electronic catalogue – for easy searching. Simply enter your application-specific requirements and let our system guide you quickly and reliably to an appropriate solution. www.festo.com/medienbestaendigkeit

Festo AG & Co. KG

Ruiter Strasse 82
73734 Esslingen
www.festo.com

Tel. +49 711 347-0

Fax +49 711 347-2144

service_international@festo.com