

Massive savings on package deals

Choose your package and order now!

| Star Essentials Package 1 | |
|---------------------------|------------|
| Net price excl. VAT | R 8 699,00 |
| Part number to order | 23143330 |

| Star Essentials Package 2 | |
|---------------------------|------------|
| Net price excl. VAT | R16 499,00 |
| Part number to order | 23143365 |

| Star Essentials Package 3 | |
|---------------------------|------------|
| Net price excl. VAT | R29 999,00 |
| Part number to order | 23143374 |

Our special gift to you

FREE ZRS tubing cutters with any package 2 or 3 purchased.



More Information & How to Order

To place your order:

Tel: 08600 FESTO (33786)

Email: sales.za@festo.com

More information on Didactic courses:

Tel: +27 11 971 5536

Email: didactictac.za@festo.com

Website: www.festo-didactic.com/za-en/training-and-consulting/courses

Terms & Conditions

Fitting & Tubing Packages

- The fitting and tubing package promotion is valid from 15th October 2018 to 31st January 2019.
- Once purchased, the 'star' maintenance packages are not refundable – in part, or in full.
- Although individual parts are generally held ex-stock in South Africa, delivery periods are subject to prior sales and stock availability at the time of order.
- This promotion is only valid for customers in South Africa.

Didactic Training Course Discount Vouchers

- The Didactic Course promotion is valid until 31st July 2019.
- This promotion does not run concurrently with any other Didactic Training promotion.
- The 4 training courses applicable to this promotion are Basic Pneumatics, Maintenance Pneumatics, Electro Pneumatics and Energy Saving Pneumatics.
- Discounts are applicable to advertised prices at the time of course booking.
- Course availability is not guaranteed and is subject to bookings at the time of application.
- All bookings will be done on a "first come first served" basis.

★ Festo core product range covers 80% of your automation tasks

Worldwide: Always in stock
Superb: Festo quality at an attractive price
Easy: Just a few clicks to place an order online
Fast: Quick and easy delivery

FESTO

Don't let damaged fittings and tubing result in expensive production losses.



'Star' Maintenance Essentials

3 PACKAGES • DISCOUNTED PRICES • LIMITED OFFER

Keeping your machines in perfect running condition means avoiding unnecessary costs and downtime. Take advantage of Festo's 'Star' Maintenance Essentials - a perfect mix of the most commonly used fittings, connectors and tubing sizes across the pneumatic control chain.


Don't miss out! Choose one of three exceptional package price deals today!

PUN-HT Transparent Tubing

Festo's PUN-HT tubing provides for fast connection in pneumatic installations.

Unique properties:

- Reliable air supply in moist environments**
 Suitable for compressed air and vacuum media, PUN-HT is also water resistant allowing application in wet areas and environments with high moisture levels.
- Highly versatile**
 Not only is the tubing kink-resistant and easy to install, its resistance to hydrolysis and microbes makes it perfect for use in the food industry. (Visit the website for manufacturers declaration)
- Transparent for greater reliability**
 PUN-HT's transparent colour makes it easy to detect solid particles, moisture and oil. This feature ensures simple monitoring of compressed air quality, allowing preventative maintenance measures to be taken before damage is done to pneumatic components.

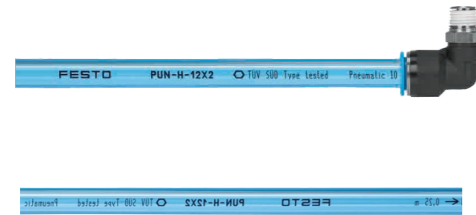

QS Fittings and Connectors

The QS series provides a flexible mix of easy to select components for a wide variety of standard applications.

Unique properties:

- Simple “plug and work” design**
 The stainless steel retaining claw within the fittings and connectors holds the tubing securely without damaging its surface. This allows vibration and pressure surges to be safely absorbed.
- Excellent sealing properties**
 A nitrile rubber sealing ring (NBR) guarantees a perfect seal between the tubing and the body of the fitting or connector. Fittings with ISO R threads include a self-sealing PTFE coating which allows the fitting to be re-used up to five times without the need for additional sealing materials.
- Resistant to corrosion**
 The brass bodies and threaded plugs are nickel plated and are therefore highly resistant to corrosion.
- Orientable**
 Once installed, QS fittings and connectors can be easily aligned to accommodate tubing entry and exit.



Your Didactic Course Choices

Your FREE Didactic training vouchers entitle you to huge discounts on the following four courses.

PN111 - Pneumatics (1) - Basic

This course covers the fundamental principles, methods, components and circuitry in pneumatic automation technology.

Requirements: Technical understanding

Duration: 3-day course

Accreditation: NQF Level 3

PN121- Pneumatics (2) Maintenance

Expand your pneumatic maintenance knowledge through practical exercises on training equipment for the setting up, commissioning and troubleshooting of installations.

Requirements: Pneumatics (1) Basic Course

Duration: 3-day course

Accreditation: NQF Level 3

PN211- Electro-Pneumatics

Following this course, you will understand the functional relationship between pneumatic and electrical components and be able to successfully design an electro-pneumatic system.

Requirements: Basic knowledge of control technology : Pneumatic (1) Basic Course

Duration: 3-day course

Accreditation: NQF Level 4

PN361-Energy Saving in Pneumatic Systems

This course focuses attention on cost-saving and maximizing energy efficiency in compressed air production, distribution, preparation and pneumatic circuits.

Requirements: Pneumatics (1) Basic Course

Duration: 2-day course

Package Contents

| Fittings & Connectors - Type QS | | | | | | | | |
|--|-----------------------------|------------------|------------------|-----------------|-------------------------|---------------------------|----------------------------|------------------------|
| Type Code | Description | Design | Connection 1 | Connection 2 | Package 1 QTY | Package 2 QTY | Package 3 QTY | |
| QS-1/8-6 | Push-in Fitting | Straight shape | R1/8 Male Thread | 6mm Push-in | 10 | 20 | 40 | |
| QS-1/4-6 | Push-in Fitting | Straight shape | R1/4 Male Thread | 6mm Push-in | 10 | 20 | 40 | |
| QS-1/8-8 | Push-in Fitting | Straight shape | R1/8 Male Thread | 8mm Push-in | 10 | 20 | 40 | |
| QS-1/4-8 | Push-in Fitting | Straight shape | R1/4 Male Thread | 8mm Push-in | 10 | 20 | 40 | |
| QS-1/4-10 | Push-in Fitting | Straight shape | R1/4 Male Thread | 10mm Push-in | 10 | 20 | 40 | |
| QSL-1/8-6 | Push-in 'L' Fitting | L-shape | R1/8 Male Thread | 6mm Push-in | 10 | 20 | 40 | |
| QSL-1/4-6 | Push-in 'L' Fitting | L-shape | R1/4 Male Thread | 6mm Push-in | 10 | 20 | 40 | |
| QSL-1/8-8 | Push-in 'L' Fitting | L-shape | R1/8 Male Thread | 8mm Push-in | 10 | 20 | 40 | |
| QSL-1/4-8 | Push-in 'L' Fitting | L-shape | R1/4 Male Thread | 8mm Push-in | 10 | 20 | 40 | |
| QSL-1/4-10 | Push-in 'L' Fitting | L-shape | R1/4 Male Thread | 10mm Push-in | 10 | 20 | 40 | |
| QS-6 | Push-in Connector | Straight shape | 6mm Push-in | 6mm Push-in | 10 | 20 | 40 | |
| QS-8 | Push-in Connector | Straight shape | 8mm Push-in | 8mm Push-in | 10 | 20 | 40 | |
| QS-10 | Push-in Connector | Straight shape | 10mm Push-in | 10mm Push-in | 10 | 20 | 40 | |
| QSL-6 | Push-in 'L' Connector | L-shape | 6mm Push-in | 6mm Push-in | 10 | 20 | 40 | |
| QSL-8 | Push-in 'L' Connector | L-shape | 8mm Push-in | 8mm Push-in | 10 | 20 | 40 | |
| QSL-10 | Push-in 'L' Connector | L-shape | 10mm Push-in | 10mm Push-in | 10 | 20 | 40 | |
| QST-6 | Push-in 'T' Connector | T-shape | 6mm Push-in | 6mm Push-in | 10 | 20 | 40 | |
| QST-8 | Push-in 'T' Connector | T-shape | 8mm Push-in | 8mm Push-in | 10 | 20 | 40 | |
| QST-10 | Push-in 'T' Connector | T-shape | 10mm Push-in | 10mm Push-in | 10 | 20 | 40 | |
| Transparent Pneumatic Tubing - Type PUN-HT | | | | | | | | |
| Type Code | Description | Colour | Outside Diameter | Inside Diameter | Package 1 QTY | Package 2 QTY | Package 3 QTY | |
| PUN-H-6X1-TBL | Hydrolysis Resistant Tubing | Translucent Blue | 6mm | 4mm | 50m | 100m | 200m | |
| PUN-H-8X1.25-TBL | Hydrolysis Resistant Tubing | Translucent Blue | 8mm | 5.7mm | 50m | 100m | 200m | |
| PUN-H-10X1.5-TBL | Hydrolysis Resistant Tubing | Translucent Blue | 10mm | 7mm | 50m | 100m | 200m | |
| ZRS | Pipe and Tubing Cutter | - | - | - | 0 | 1 | 2 | |
| Training Discounts | | | | | | | | |
| Didactic Course Training Vouchers - Massive savings on selected courses for yourself or a colleague! | | | | | 5% off for one delegate | 10% off for two delegates | 20% off for four delegates | |
| What do your Didactic training discounts equate to in monetary terms? | | | | | Price Excl. VAT | Saving Value Package 1 | Saving Value Package 2 | Saving Value Package 3 |
| Basic Pneumatics | | | | | R7 800.00 | R390.00 | R1 560.00 | R6 240.00 |
| Maintenance Pneumatics | | | | | R8 100.00 | R405.00 | R1 620.00 | R6 480.00 |
| Electro Pneumatics | | | | | R8 100.00 | R405.00 | R1 620.00 | R6 480.00 |
| Energy Saving Pneumatics | | | | | R5 250.00 | R262.50 | R1 050.00 | R4 200.00 |