


Parallel kit EAMM-U-86-D40-87A-102-S1

Part number: 1215814

FESTO

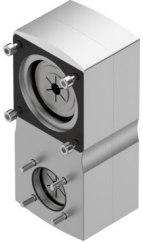

 [General operating condition](#)

Data sheet

| Feature | Value |
|---------------------------------------|-----------------------|
| Size | 86 |
| Mounting position | Any |
| Gear unit ratio | 1:1 |
| Max. rotational speed | 5000 rpm |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95% |
| Degree of protection | IP65 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 175 kgmm ² |
| Frictional torque independent of load | 0.25 Nm |
| Transmittable torque | 9.5 Nm |
| Product weight | 2530 g |
| Interface code, actuator | D40B |
| Interface code, motor in | 87A |
| Note on materials | RoHS compliant |