


Axial kit EAMM-A-D32-40A-S1

Part number: 1322178

FESTO

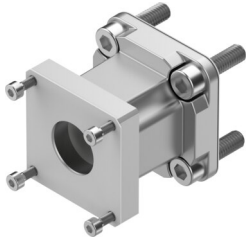

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	41.3 mm
Mounting position	Any
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	0.28 kgmm ²
Transmittable torque	1.6 Nm
Product weight	130 g
Interface code, actuator	D32
Interface code, motor in	40A
Note on materials	RoHS compliant