


# Blanking plug QSP17-PTB

Part number: 172996

FESTO

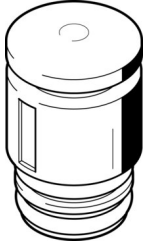

## Data sheet

 [General operating condition](#)

Feature	Value
Size	Standard
Mounting position	Any
Design	Straight design
Size of pack	1
Operating pressure complete temperature range	0.095 MPa ... 1 MPa
Operating pressure complete temperature range	0.95 bar ... 10 bar
Operating pressure complete temperature range	13.775 psi ... 145 psi
Maritime classification	See certificate
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Product weight	4.7 g
Type of mounting	Mounting pin
Pneumatic connection, port 1	Cartridge 17 mm
Note on materials	RoHS compliant
Material housing	Process automation
Material tubing seal	NBR