


# Swivel flange CRSNCS-63

Part number: 2895923

FESTO

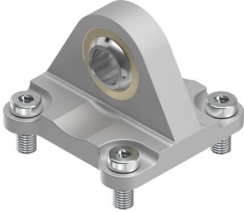

 [General operating condition](#)

## Data sheet

| Feature  | Value  |
|--|--|
| Size   | 63   |
| Based on standard                                  | ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)  |
| Variants   | High corrosion protection  |
| Corrosion resistance class CRC                     | 4 - Very high corrosion stress   |
| LABS (PWIS) conformity                             | VDMA24364-B2-L   |
| Suitability for the production of Li-ion batteries | Metals with more than 5% by mass of copper, zinc or nickel are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils. |
| Ambient temperature                                | -40 °C ... 150 °C  |
| Max. load capacity                                 | 4 kN   |
| Product weight                                     | 576 g  |
| Note on materials                                  | RoHS compliant   |
| Material mounting                                  | High-alloy stainless steel   |
| Material rod end bearing                           | PTFE<br>Stainless steel  |
| Material screws                                    | High-alloy stainless steel   |