


Plug socket with cable KMF-1-24DC-2.5-LED

Part number: 30935

FESTO

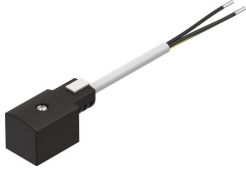

 [General operating condition](#)

Data sheet

Feature	Value
Switching position indicator	LED
Type of mounting	On solenoid valve via M3 central screw
Mounting position	Any
Product weight	170 g
Electrical connection	Socket
Nominal operating voltage DC	24 V
Protective conductor connection	Available
Cable length	2.5 m
Cable diameter	6 mm
Cable structure	3 x 0.75 mm ²
Degree of protection	IP67 To IEC 60529
Ambient temperature	-20 °C ... 80 °C
CE mark (see declaration of conformity)	In accordance with EU RoHS Directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B2-L
Material cable sheath	PVC
Material housing	Makrolon® POM
Material electrical contact	Bronze