


# Coupling piece KSG-M12X1,25

Part number: 32964

FESTO

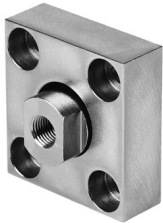

 [General operating condition](#)

## Data sheet

| Feature  | Value  |
|--|--|
| Size   | M12x1.25   |
| Mounting position                                  | optional   |
| Threaded connection                                | Female thread M12x1.25   |
| Corrosion resistance class CRC                     | 1 - Low corrosion stress   |
| LABS (PWIS) conformity                             | VDMA24364-B2-L   |
| Suitability for the production of Li-ion batteries | Metals with more than 1% by mass of copper are excluded from use. Exceptions are printed circuit boards, cables, electrical plug connectors and coils. |
| Ambient temperature                                | -40 °C ... 150 °C  |
| Product weight                                     | 447 g  |
| Note on materials                                  | RoHS-compliant   |
| Material mounting                                  | Steel<br>Galvanised  |
| Material thread piece                              | Steel<br>Galvanised  |