


# Foot mounting HNA-80-R3

Part number: 537260

FESTO

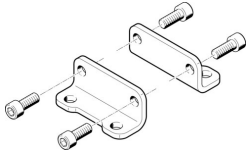

 [General operating condition](#)

## Data sheet

| Feature  | Value  |
|--|--|
| Size   | 80   |
| Based on standard                                  | ISO 21287  |
| Variants   | High corrosion protection  |
| Corrosion resistance class CRC                     | 3 - high corrosion stress  |
| LABS (PWIS) conformity                             | VDMA24364-B2-L   |
| Suitability for the production of Li-ion batteries | Metals with more than 5% by mass of copper, zinc or nickel are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils. |
| Product weight                                     | 634 g  |
| Note on materials                                  | RoHS-compliant   |
| Material bracket                                   | Steel<br>With protective coating   |