


# Moment compensator FKC-40

Part number: 538962

FESTO

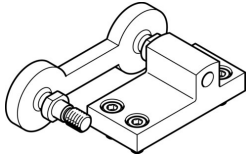

 [General operating condition](#)

## Data sheet

Feature	Value
Size	40
Radial deviation +/-	2.5 mm
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Max. permissible short-term load in force direction +/-	3000 N
Max. permissible long-term load in force direction +/-	1400 N
Product weight	180.2 g
Note on materials	RoHS-compliant
Material joint	PA-reinforced
Material on ball stud	High-alloy steel
Material plate	Wrought aluminium alloy