


# Supply plate VMPA-FB-SP-V

Part number: 541082

FESTO

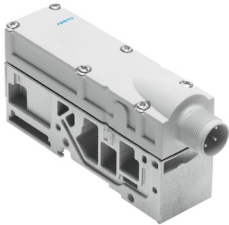

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal operating voltage DC	24 V
Permissible voltage fluctuations	+/- 25%
Approval	c UL us - Recognized (OL)
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65
Ambient temperature	-5 °C ... 50 °C
Product weight	200 g
Electrical connection	3-pin M18
Note on materials	RoHS-compliant
Material cover	PA-reinforced
Material housing	Die-cast aluminium