


# Axial kit EAMM-A-D40-87A

Part number: 550982

FESTO

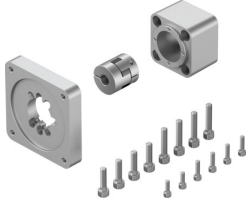

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	54 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	5.87 kgmm <sup>2</sup>
Transmittable torque	12.5 Nm
Product weight	530 g
Interface code, actuator	D40 D40C
Interface code, motor in	87A
Note on materials	RoHS compliant