


# Fixed flow restrictor-SET VMPA1-FT-NW0.3-1.7

Part number: 572543

FESTO

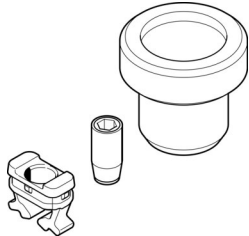

 [General operating condition](#)

## Data sheet

Feature	Value
Valve function	Flow control function
Pneumatic connection, port 1	Sub-base
Type of mounting	Clamped
Standard nominal flow rate in flow control direction	3.5 l/min ... 115 l/min
Operating pressure	-0.009 MPa ... 0.1 MPa
Operating pressure	-0.09 bar ... 1 bar
Ambient temperature	-5 °C ... 60 °C
Size	10
Nominal size	0.3 mm ... 1.7 mm
Mounting position	optional
Size of pack	2
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C ... 40 °C
Media temperature	-5 °C ... 60 °C
Product weight	0.6 g
Note on materials	RoHS-compliant
Material retaining bracket	POM
Material hollow bolt	Wrought aluminium alloy