


Vertical pressure exhaust plate VABF-L1-P7A13-M7

Part number: 574594

FESTO

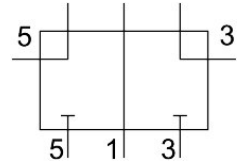

[PDF](#) General operating condition

Data sheet

Feature	Value
Grid dimension	10.5 mm
Max. number of valve positions	1
Symbol	00995307
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Approval	RCM trademark c UL us - Recognized (OL)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque for valve mounting	0.45 Nm
Product weight	220 g
Pneumatic connection, port 3	M7
Pneumatic connection, port 5	M7
Note on materials	RoHS-compliant
Material plate	Wrought aluminium alloy