


# Vertical pressure exhaust plate VABF-L1-P7A13-G18

FESTO

Part number: 574595

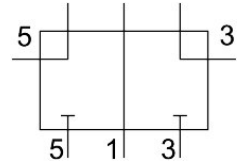

[PDF](#) General operating condition

## Data sheet

Feature	Value
Grid dimension	16 mm
Max. number of valve positions	1
Symbol	00995307
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Approval	RCM trademark c UL us - Recognized (OL)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque for valve mounting	0.65 Nm
Product weight	350 g
Pneumatic connection, port 3	G1/8
Pneumatic connection, port 5	G1/8
Note on materials	RoHS-compliant
Material plate	Wrought aluminium alloy