


Supply plate VABF-B10-20-P1A4-G18

Part number: 576492

FESTO

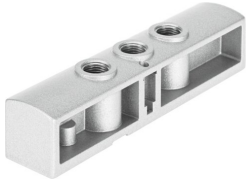

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------------|-------------------------------|
| Operating pressure | -0.09 MPa ... 1 MPa |
| Operating pressure | -0.9 bar ... 10 bar |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Max. tightening torque | 1.4 Nm |
| Product weight | 78 g |
| Type of mounting | With through-hole |
| Pneumatic connection, port 1 | G1/8 |
| Pneumatic connection, port 3 | G1/8 |
| Pneumatic connection, port 5 | G1/8 |
| Note on materials | RoHS-compliant |
| Material supply plate | Die-cast aluminium |