


# Supply plate VABF-B10-25-P1A4-G14

Part number: 8026318

FESTO

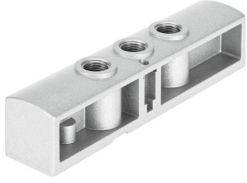

 [General operating condition](#)

## Data sheet

Feature	Value
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque	3 Nm
Product weight	110 g
Type of mounting	With through-hole
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 5	G1/4
Note on materials	RoHS-compliant
Material supply plate	Die-cast aluminium