


Common supply manifold VABM-B10-30-G34-4-P53-E

Part number: 8026358

FESTO

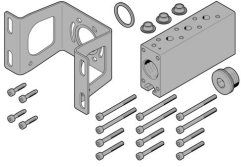

 [General operating condition](#)

Data sheet

Feature	Value
Grid dimension	32 mm
Mounting position	optional
Max. number of valve positions	4
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	1169 g
Type of mounting	Via mounting bracket
Pneumatic connection, port 1	G3/4
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy